

See-Through Peel Pouches & Rolls

S - Flat Pouches

For packing individual instruments, smaller sets and other items. (STEAM, EO, FO)

Art.code	Size (mm)	Pieces/case
S 17	50 x 200	3.600
S 1	50 x 250	2.400
S 24	75 x 150	2.400
S 2	75 x 200	2.400
S 23	75 x 230	1.800
S 4	75 x 270	3.600
S 18	75 x 300	4.200
S 22	75 x 520	2.400
S 25	100 x 150	2.400
S 3	100 x 200	1.800
S 5	100 x 270	3.000
S 8	100 x 300	1.200
S 19	100 x 350	1.200
S 9	100 x 400	1.200
S 12	100 x 570	1.800
S 27	120 x 400	1.200
S 15	150 x 200	1.200
S 6	150 x 270	1.800
S 20	150 x 300	1.800
S 26	150 x 350	1.800
S 13	150 x 400	1.200
S 28	150 x 520	1.200
S 34	160 x 600	1.200
S 33	180 x 320	1.000
S 7	205 x 270	600
S 7 A	205 x 340	1.000
S 10	205 x 400	600
S 10 A	205 x 440	600
S 35	205 x 600	1.200
S 2070	205 x 700	600
S 2244	220 x 440	600
S 16	250 x 380	1.200
S 11	250 x 500	600
S 36	250 x 600	500
S 37	250 x 700	600
S 29	270 x 350	600
S 30	270 x 440	600
S 21	300 x 500	600
S 14	300 x 570	600
S 38	320 x 500	600
S 31	420 x 500	500
S 32	420 x 600	500



S-D - Flat Pouches

(STEAM, EO, FO)

Art.code	Size (mm)	Pcs Per Shipper Box	Pcs per dispenser
S1-D	50 x 250	1000	200
S13-D	150 x 400	1000	200
S16-D	250 x 380	600	200
S18-D	75 x 300	2000	200
S2-D	75 x 200	1000	200
S20-D	150 x 300	1000	200
S24-D	75 x 150	2000	200
S26-D	150 x 350	1000	200
S3-D	100 x 200	1000	200
S4-D	75 x 270	1000	200
S5-D	100 x 270	1000	200
S6-D	150 x 270	1000	200
S8-D	100 x 300	1000	200
S9-D	100 x 400	1000	200

SdV/SSdV - Pouches for robotic instruments

for packing instruments used in a robotic surgery, and for other long devices.

Art.code	Size (mm)	Pieces/case
SdV10	200 x 800	400
SdV20	250 x 900	400
SSdV10*	200 x 800	400
SSdV20*	250 x 875	400

*with adhesive closure



B - Pouches with Gusset

For more voluminous items. (STEAM, EO, FO)

Art.code	Size (mm)	Pieces/case
B 35	100 x 50 x 300	500
B 30	100 x 50 x 360	500
B 31	150 x 50 x 400	500
B 32	150 x 50 x 460	500
B 36	200 x 55 x 400	250
B 33	200 x 55 x 500	250
B 37	250 x 65 x 480	250
B 34	300 x 80 x 550	250
B 38	420 x 100 x 570	250



See-Through Peel Pouches & Rolls

R - Flat Rolls (STEAM, EO, FO)

Art.code	Size (mm)	Pieces/case
R 39	50 : 200 m	5
R 40	75 : 200 m	4
R 41	100 : 200 m	3
R 125	125 : 200 m	2
R 42	150 : 200 m	2
R 43	200 : 200 m	1
R 44	250 : 200 m	1
R 45	300 : 200 m	1
R 46	350 : 200 m	1
R 47	400 : 200 m	1

Art.code	Size (mm)	Pieces/case
R 39/100	50 : 100 m	8
R 40/100	75 : 100 m	8
R 41/100	100 : 100 m	4
R 42/100	150 : 100 m	2
R 43/100	200 : 100 m	2
R 44/100	250 : 100 m	2
R 45/100	300 : 100 m	1
R 47/100	400 : 100 m	1
R 49/100	500 : 100 m	1

Art.code	Size (mm)	Pieces/case
R 39/31	50 : 31 m	10
R 40/31	75 : 31 m	10
R 41/31	100 : 31 m	10
R 42/31	150 : 31 m	16
R 43/31	200 : 31 m	6
R 44/31	250 : 31 m	6
R 45/31	300 : 31 m	6

RB - Rolls with Gusset (STEAM, EO, FO)

Art.code	Size (mm)	Pieces/case
RB 50	75 x 25 : 100 m	4
RB 51	100 x 50 : 100 m	3
RB 52	150 x 50 : 100 m	2
RB 53	200 x 55 : 100 m	1
RB 54	250 x 65 : 100 m	1
RB 55	300 x 80 : 100 m	1
RB 56	350 x 80 : 100 m	1
RB 57	400 x 80 : 100 m	1

RR - Reinforced Rolls (STEAM, EO, FO)

Art.code	Size (mm)	Pieces/case
RR41	100mm : 100m	2
RR43	200mm : 100m	1
RR45	300mm : 100m	1
RR47	400mm : 100m	1
RR49	500mm : 100m	1



SS - Standard Self Seal Pouches

with adhesive closure.


Art.code	Size (mm)	Pieces/case
SS 10	60 x 250	1.000
SS 1	90 x 200	1.000
SS 2	90 x 250	1.000
SS 3	90 x 570	1.000
SS 4	130 x 270	1.000
SS 4 A	130 x 380	1.000
SS 5	200 x 350	1.200
SS 5 A	190 x 330	1000
SS 6	250 x 400	600
SS 7	300 x 450	600



SNW - TEX-Line Pouches

Peel pouches with nonwoven and film for packing heavy and bulky items. (STEAM, EO, FO)

Art.code	Size (mm)	Pieces/case
SNW 2040	205 x 400	500
SNW 2744	270 x 440	500
SNW 3250	320 x 500	500
SNW 4260	420 x 600	300
SNW 5065	500 x 650	200
SNW 5075	500 x 750	200
SNW 5775	570 x 750	200

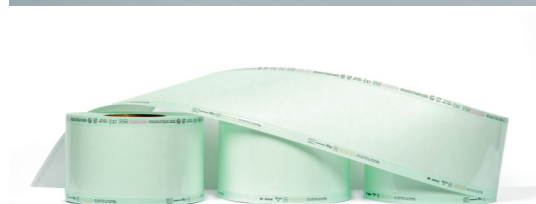

CB - Dust Cover Bags

for use after sterilization.

Art.code	Size (mm)	Pieces/case
CB 1	150 x 270	1.000
CB 2	205 x 300	1.000
CB 3	250 x 400	1.000
CB 4	300 x 500	500
CB 5	400 x 550	500
CB 6	420 x 700	500
CB 7	500 x 800	300

SSDC - Self Seal Dust Cover Bags

with adhesive closure.

Art.code	Size (mm)	Pieces/case
SSDC 10	150 x 270	500
SSDC 20	200 x 350	500
SSDC 30	250 x 400	500
SSDC 40	300 x 550	200
SSDC 60	420 x 700	200



LTS - Flat Pouches

Made with DuPont™ Tyvek® for low temperature sterilization. Printed with hydrogen plasma process indicator.

Art.code	Size (mm)	Pieces/case
LTS 7520	75 x 200	1.000
LTS 1025	100 x 250	1.000
LTS 1530	150 x 300	1.000
LTS 1644	160 x 440	600
LTS 1660	160 x 600	600
LTS 2038	205 x 390	1.200
LTS 2538	250 x 390	600
LTS 2550	250 x 500	600

LTSS - Self Seal Pouches

Made with DuPont™ Tyvek® for low temperature sterilization. Printed with hydrogen plasma process indicator.

Art.code	Size (mm)	Pieces/case
LTSS 1	90 x 200	1.000
LTSS 2	90 x 250	1.000
LTSS 4	130 x 270	1.000
LTSS 4 A	130 x 380	1.000
LTSS 5 A	190 x 330	1.000
LTSS 6	250 x 400	600
LTSS 7	300 x 450	600

LTR - Flat Rolls

Made with DuPont™ Tyvek® for low temperature sterilization. Printed with hydrogen plasma process indicator.

Art.code	Size (mm)	Pieces/case
LTR 40	75 x 100	2
LTR 41	100 x 100	2
LTR 42	150 x 100	1
LTR 43	200 x 100	1
LTR 43 A	225 x 100	1
LTR 44	250 x 100	1
LTR 45	300 x 100	1
LTR 46	350 x 100	1
LTR 47	400 x 100	1
LTR 49	500 x 100	1

Tyvek® is registered trademark of DuPont™.



SMX - High Performance ProWraps

SMX-1 Blue Light

For small and medium-size trays and sets.

Art.code	Size (mm)	Pieces/case
SMX 1060	600 x 600	480
SMX 1075	750 x 750	200
SMX 1090	900 x 900	160
SMX 1100	1.000 x 1.000	160
SMX 1120	1.200 x 1.200	120
SMX 1120 / 140	1.200 x 1.400	104
SMX 1140	1.400 x 1.400	104

SMX-2 Blue Regular

For medium and large-size trays and sets and for container inner wraps.

Art.code	Size (mm)	Pieces/case
SMX 2060	600 x 600	480
SMX 2075	750 x 750	200
SMX 2090	900 x 900	120
SMX 2100	1.000 x 1.000	120
SMX 2120	1.200 x 1.200	120
SMX 2120 / 140	1.200 x 1.400	104
SMX 2140	1.400 x 1.400	104

SMX-2G Green Regular

For medium and large-size trays and sets and for container inner wraps.

Art.code	Size (mm)	Pieces/case
SMX 2G075	750 x 750	200
SMX 2G090	900 x 900	120
SMX 2G100	1.000 x 1.000	120
SMX 2G120	1.200 x 1.200	120

SMX-3 Blue Heavy Duty

Heavier structure for the most demanding applications.

Art.code	Size (mm)	Pieces/case
SMX 3060	600 x 600	416
SMX 3075	750 x 750	120
SMX 3090	900 x 900	120
SMX 3100	1.000 x 1.000	120
SMX 3120	1.200 x 1.200	104

SMX-4 Blue Super Duty

Especially high thickness for orthopedic sets and other heavy-duty uses.

Art.code	Size (mm)	Pieces/case
SMX 4060	600 x 600	160
SMX 4075	750 x 750	120
SMX 4090	900 x 900	104
SMX 4100	1.000 x 1.000	104
SMX 4120	1.200 x 1.200	80

SPC - Crepe Paper

Special grade paper creped to give increased flexibility.

Art.code	Size (mm)	Pieces/case
SPC 40	400 x 400	500
SPC 50	500 x 500	500
SPC 60	600 x 600	500
SPC 75	750 x 750	250
SPC 90	900 x 900	250
SPC 100	1.000 x 1.000	250
SPC 120	1.200 x 1.200	100


Absorbent Trayliners

For use together with surgical instrument trays to avoid wet packs, protect the barrier and instruments.

TL-Standard	Size (mm)	Pieces/case
TL 25	250 x 300	1.000
TL 40	400 x 500	500
TL 50	500 x 300	500
TL 3040	300 x 400	500

TLWE-Trayliners with edge		
TLWE 2525	250 x 250	500
TLWE 4825	480 x 250	500
TLWE 5030	500 x 300	500

TLNW-Trayliners nonwoven		
TLNW 1525	150 x 250	3.200
TLNW 3025	300 x 250	1.200
TLNW 3040	300 x 400	1.200
TLNW 3050	300 x 500	600

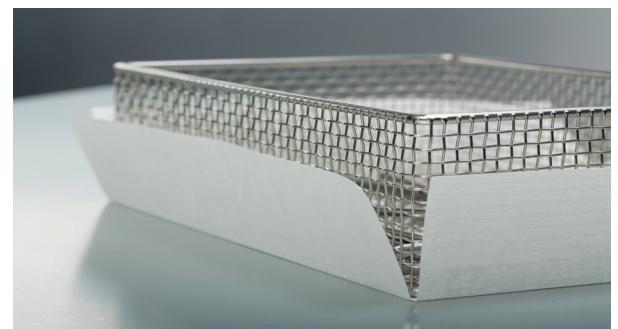

STERIKING COMBI SETS

STERIKING COMBI SET CW5 SMX1/NWL - COMBI WRAP LIGHT (37+52 gsm)		
Art.code	Size (mm)	Pieces/case
CW5075	750 x 750	240
CW5090	900 x 900	200
CW5100	1000 x 1000	144
CW5120	1200 x 1200	120
CW5120/140	1200 x 1400	120

STERIKING COMBI SET CW6 SMX2/NWL - COMBI WRAP REGULAR (47+52 gsm)		
Art.code	Size (mm)	Pieces/case
CW6075	750 x 750	240
CW6090	900 x 900	200
CW6100	1000 x 1000	144
CW6120	1200 x 1200	120

STERIKING COMBI SET CW7 SMX3/NWL - COMBI WRAP HEAVY DUTY (55+52 gsm)		
Art.code	Size (mm)	Pieces/case
CW7075	750 x 750	240
CW7090	900 x 900	200
CW7100	1000 x 1000	144
CW7120	1200 X 1200	120

STERIKING COMBI SET CW8 SMX4/NWL - COMBI WRAP SUPER DUTY (75+52 gsm)		
Art.code	Size (mm)	Pieces/case
CW8120	1200 x 1200	120

STERIKING COMBI SET CW10 SMX4/SMX2G (75+47 gsm)		
Art.code	Size (mm)	Pieces/case
CW10075	750 x 750	120
CW10090	900 x 900	104
CW10100	1000 x 1000	104
CW10120	1200 x 1200	80
CW10140	1400 x 1400	80



Indicator Strips

AC = steam, EO-gas, and
PL = low temperature plasma.

Art.code	Strips/dispenser	Pieces/case
AC 6	250	
AC 250/500	250	1.000
EO 250	250	1.000
PL 500		500

Daily Test Pack

The ready made test packs for Bowie & Dick Test.

Art.code	Pieces/case
DCG2	20
DC 20	20

Helix Challenge Test

For a charge control and as a steam penetration test for hollow instruments with small lumina.

Art.code	Strips/dispenser	Pieces/case
HX 100	100	25
HX 400	400	25

Tapes

Indicator Tapes, S = steam, E = EO-gas, H = hot-air indicator, P = plasma and L = latex free

Art.code	Width/length	Pieces/case
ITS 19 GL	19 mm x 50 m	48
ITS 25 GL	25 mm x 50 m	36
JTB 19 S G (B = blue)	19 mm x 50 m	48
JTB 25 S G (B = blue)	25 mm x 50 m	36
ITH 19	19 mm x 50 m	48

Tape dispenser for one roll.

Art.code	Pieces/case
TDS 25	1



Steriking® other products

Sealing Machines

Model: RS 120A Rotosealer

Model: RS 300 Rotosealer with printer

Model: IS 250 Impulse sealer with cutting device

Roll Holders in 2 different widths

• RH750, RH900



Seal Control Sheet

For operational qualification of the sealing process.

Art.code	Strips/dispenser	Pieces/case
SC 250 (paper)	250	1.000
TSC 200 (Tyvek®)	200	800

Multi Seal Test

For qualification and testing of the sealing process; visual check for seal quality and dye penetration test for seal integrity.

Art.code	Pieces/case
MS 300	300

PB - Paper Bags

Heat-sealable lacquer top and steam indicator. 

Art.code	Size (mm)	Pieces/case
PB 1	90 x 50 x 125	1.000
PB 2	110 x 30 x 190	1.000
PB 3	125 x 50 x 250	1.000
PB 4	140 x 75 x 250	500
PB 5	140 x 50 x 330	500
PB 6	165 x 50 x 380	500
PB 7	180 x 95 x 380	500
PB 8	190 x 65 x 330	500
PB 9	250 x 100 x 380	500
PB 10	300 x 75 x 530	250
PB 12	380 x 125 x 610	250

HR - Hot Air Rolls



Special polyamide tubing for sterilization by dry heat.

Art.code	Width/length	Pieces/case
HR 39	50 mm x 200 m	5
HR 40	75 mm x 200 m	4
HR 41	100 mm x 200 m	3
HR 42	150 mm x 200 m	2
HR 43	200 mm x 200 m	1
HR 44	250 mm x 200 m	1




Non-toxic Markers

Waterproof, heat-resistant markers for sterilization packages.

Art.code	Color	Pieces	Size (mm)	Pieces/dispenser
MAR 1	Black		0.75	10
MAR 1T	Black		1.00	10
MAR 2	Red		0.75	10
MAR 3	Blue		0.75	10



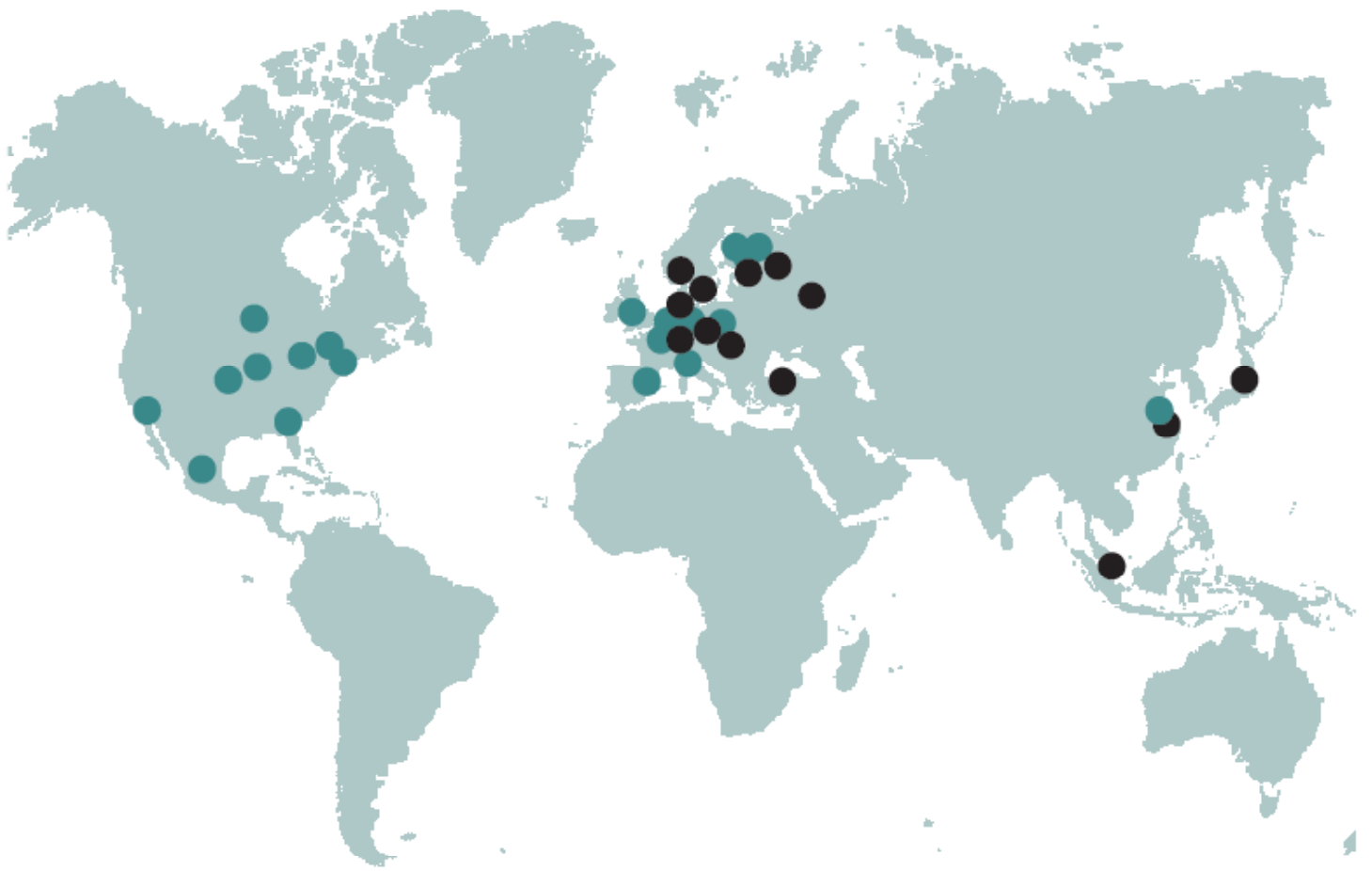

STERIKING®

We care that you pack safely!

Global Leader in Hospital Sterilization Packaging

Offering:

- Pouches & Rolls
- Wrapping Sheets
- Chemical Indicators & Tapes
- Seal Validation Products
- Sealers and Roll holders

Authorised distributor

Order Placement:

For customer service, call 1300-735-292
To fax an order, use 1800-067-639
To email an order, ordersanz@thermofisher.com

Contact Us:

For customer service, call 1300-735-292
For service and calibration, call 1300-736-767
To order online: thermofisher.com

ThermoFisher
SCIENTIFIC



Wipak Oy
www.steriking.com
e-mail: steriking@wipak.com

WIPAK