


GAS EXTRACTION PIPEWORK | PERIMETER BOREHOLES | LANDFILL GAS

GAS FLOW MEASUREMENT OPTIONS

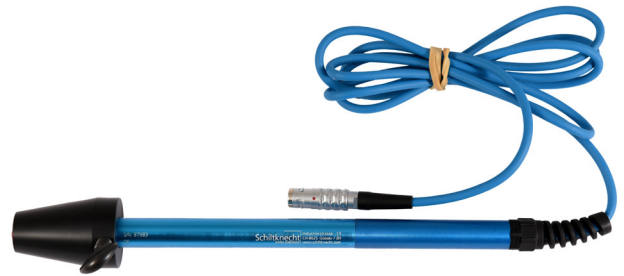

ANEMOMETER (ATEX CERTIFIED)

Designed to plug into the GA5000, GEM5000 and BIOGAS 5000 to instantly provide a flow indication.

- Measures flow ranges 0.7 to 40 m/s
- Typical accuracy +/- 1.0% full scale +/- 3.0% reading
- Head diameter 11mm
- Cable length 1.5m
- Use on gas extraction systems

INTERNAL LOW FLOW

Internal low flow is available on the GA5000 to measure low levels of flow.

- Specify at time of manufacture
- 0- 20 litres / hour
- Typical accuracy +/- 0.3 litres / hour
- Borehole low flow monitoring
- Contaminated land monitoring



PITOT TUBE

The pitot tube kit is designed to work with the GEM5000 and BIOGAS 5000 to measure pressure and high gas flow on gas extraction systems.

- Pressure readings taken in mbar
- High gas flow calculated on analyser m3/h

© Product designs and specifications are subject to change without notice. User is responsible for determining suitability of product.

Authorised distributor

In Australia:

For customer service, call 1300-735-292

To email an order, ordersau@thermofisher.com

To order online: thermofisher.com

In New Zealand:

For customer service, call 0800-933-966

To email an order, ordersnz@thermofisher.com

To order online: thermofisher.com

ThermoFisher
S C I E N T I F I C