

A logo celebrating 50 years, featuring a large '50' with a stylized globe inside the zero, and the word 'YEARS' below it, all in gold on a dark blue background.

50
YEARS



 **Texwipe®**
An *ITW* Company

Cleanroom Swabs

Microdenier | Polyester | Foam | ESD | Cotton | Specialty

Sterile | Cleaning Validation & TOC Validation Kits | Alpha® | Absorbond® | CleanFoam®
ESD-Safe | Cotton | Specialty | General Purpose

Table of Contents

| | | |
|---|---------------------------|--------|
|  | Sterile | Pg. 2 |
|  | Cleaning Validation . . . | Pg. 3 |
|  | Cleaning Validation Kits | Pg. 3 |
|  | Microdenier | Pg. 4 |
|  | Polyester | Pg. 5 |
|  | CleanFoam® | Pg. 6 |
|  | ESD-Safe | Pg. 7 |
|  | Cotton | Pg. 8 |
|  | Specialty | Pg. 9 |
|  | General Purpose . . . | Pg. 10 |

Our highly professional team will help you select and develop products for any critical environment application. Contact information is located on the back of this brochure or visit us at www.texwipe.com.

About Texwipe

Texwipe's commitment to innovation, leadership and quality in cleanroom consumable products spans more than fifty years. We invest in technology to respond to our customers' evolving needs in contamination control.



Texwipe's Core Values are:

- **Innovation** – Texwipe pioneers the latest technologies to provide innovation in contamination control products and processes.
- **Quality** – Texwipe product quality is maintained by the most advanced testing and quality control standards in the industry.
- **Technology Leadership** – Texwipe leads our industry in testing metrology, methods and processes to reduce contamination.

Throughout Texwipe's global operations, we support our customers with products designed to exceed the requirements for cleanroom consumable products. Our highly professional team will help you select and develop products for any critical environment application.

Texwipe CleanTips®

Texwipe Cleanroom Swabs, with their trademark green handles, are the standard in cleanrooms across the globe. Engineered for superior cleanliness and consistency for a variety of applications, Texwipe has a swab that will provide the best contamination performance available.

Our products range from Microdenier, Polyester, CleanFoam®, ESD-Safe, General Purpose, Cotton and our Specialty line featuring the pre-wetted CrushTube™ Swab.

Texwipe Cleanroom Swabs are manufactured with a complete thermal bond, eliminating adhesive contamination*. Our swabs are manufactured using high-precision automated processes, resulting in swabs constructed to exacting and consistent tolerances, lot coded for traceability and quality control.

Custom Swabs

At Texwipe® we understand that the best swab for your application may be something unique. We can create a custom swab for your specific applications.

Sterile Swabs

We can create sterile versions of all Texwipe swabs or something unique and specific to your application.

*excludes Cotton Swabs



www.texwipe.com

Texwipe is certified to ISO 9001 and ISO 13485

Sterile Swabs

Texwipe's Sterile Swabs are available in USP-grade cotton, polyurethane foam and medical-grade spun polyester. The swabs are made to exacting and consistent tolerances using high-precision automated processes. The easy-to-open, individually wrapped swabs ensure sterility at point-of-use. The swabs are visible through clear packaging which also offers visibility of seal integrity.



Cotton Series

| Part No. STX705P | Head Width | Head Thickness | Head Length | Handle Width | Handle Thickness | Handle Length | Total Swab Length | Packaging |
|-------------------------|-------------------|-------------------|--------------------|-------------------|-------------------|---------------------|---------------------|--|
| | 6.4mm (0.252") | 6.4mm (0.252") | 18.2mm (0.717") | 2.5mm (0.098") | 2.5mm (0.098") | 137.0mm (5.394") | 155.0mm (6.102") | 1 swab per sleeve 50 swabs per box 10 boxes per case |




| Part No. STX705W | Head Width | Head Thickness | Head Length | Handle Width | Handle Thickness | Handle Length | Total Swab Length | Packaging |
|-------------------------|-------------------|-------------------|--------------------|-------------------|-------------------|---------------------|---------------------|--|
| | 6.0mm (0.236") | 6.0mm (0.236") | 18.2mm (0.717") | 2.5mm (0.098") | 2.5mm (0.098") | 137.0mm (5.394") | 155.0mm (6.102") | 1 swab per sleeve 50 swabs per box 10 boxes per case |



Foam Series

| Part No. STX708A | Head Width | Head Thickness | Head Length | Handle Width | Handle Thickness | Handle Length | Total Swab Length | Packaging |
|-------------------------|--------------------|-------------------|--------------------|-------------------|-------------------|---------------------|---------------------|--|
| | 19.7mm (0.776") | 9.4mm (0.370") | 26.4mm (1.040") | 6.6mm (0.260") | 3.2mm (0.126") | 105.8mm (4.165") | 132.2mm (5.205") | 1 swab per sleeve 50 swabs per box 10 boxes per case |

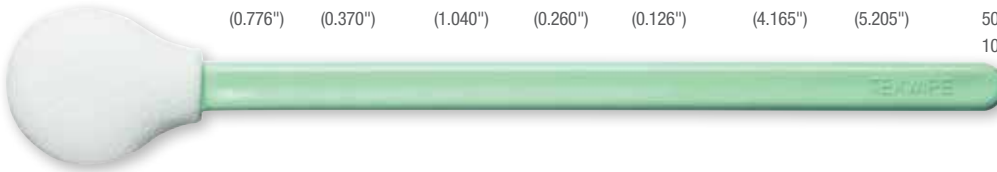

| Part No. STX712A | Head Width | Head Thickness | Head Length | Handle Width | Handle Thickness | Handle Length | Total Swab Length | Packaging |
|-------------------------|--------------------|-------------------|--------------------|-------------------|-------------------|---------------------|---------------------|--|
| | 12.7mm (0.500") | 7.8mm (0.307") | 25.7mm (1.012") | 5.2mm (0.205") | 3.0mm (0.118") | 101.8mm (4.008") | 127.5mm (5.020") | 1 swab per sleeve 50 swabs per box 10 boxes per case |



Polyester Series

| Part No. STX763 | Head Width | Head Thickness | Head Length | Handle Width | Handle Thickness | Handle Length | Total Swab Length | Packaging |
|------------------------|-------------------|-------------------|--------------------|-------------------|-------------------|---------------------|---------------------|--|
| | 5.8mm (0.228") | 5.8mm (0.228") | 18.0mm (0.709") | 2.5mm (0.098") | 2.5mm (0.098") | 137.0mm (5.394") | 155.0mm (6.102") | 1 swab per sleeve 50 swabs per box 10 boxes per case |



| Part No. STX764 | Head Width | Head Thickness | Head Length | Handle Width | Handle Thickness | Handle Length | Total Swab Length | Packaging |
|------------------------|-------------------|-------------------|--------------------|-------------------|-------------------|---------------------|---------------------|--|
| | 4.6mm (0.181") | 4.6mm (0.181") | 17.0mm (0.669") | 2.5mm (0.098") | 2.5mm (0.098") | 137.0mm (5.394") | 155.0mm (6.102") | 1 swab per sleeve 50 swabs per box 10 boxes per case |




Cleaning Validation Swabs

Engineered to deliver consistent and accurate sample recovery for cleaning validation for both specific (HPLC, UV-Vis, IMS) and nonspecific (TOC) analytical methods. The swabs are effective with a wide range of diluents.


Alpha®

Alpha series swab additionally processed to <50 µg/L TOC per swab.


| Part No. TX714K | Head Width | Head Thickness | Head Length | Handle Width | Handle Thickness | Handle Length | Total Swab Length | Packaging |
|------------------------|--------------------|-------------------|--------------------|-------------------|-------------------|---------------------|---------------------|--------------------------------------|
| | 12.7mm (0.500") | 4.2mm (0.165") | 25.7mm (1.012") | 5.2mm (0.205") | 3.0mm (0.118") | 101.8mm (4.008") | 127.5mm (5.020") | 20 swabs per bag 50 bags per case |

 

| Part No. TX715 | Head Width | Head Thickness | Head Length | Handle Width | Handle Thickness | Handle Length | Total Swab Length | Packaging |
|-----------------------|--------------------|-------------------|--------------------|-------------------|-------------------|---------------------|---------------------|---|
| | 12.7mm (0.500") | 4.2mm (0.165") | 25.7mm (1.012") | 5.2mm (0.205") | 3.0mm (0.118") | 101.8mm (4.008") | 127.5mm (5.020") | 100 swabs per bag 2 inner bags of 50 swabs 10 bags per case |

 


| Part No. TX761K | Head Width | Head Thickness | Head Length | Handle Width | Handle Thickness | Handle Length | Total Swab Length | Packaging |
|------------------------|-------------------|-------------------|--------------------|-------------------|-------------------|---------------------|---------------------|--------------------------------------|
| | 6.8mm (0.268") | 2.8mm (0.110") | 16.8mm (0.661") | 3.2mm (0.126") | 3.2mm (0.126") | 145.5mm (5.728") | 162.3mm (6.390") | 20 swabs per bag 50 bags per case |

 

Absorbond®

Surfactant-free Absorbond Series swab for HPLC/IMS analysis.

| Part No. TX716 | Head Width | Head Thickness | Head Length | Handle Width | Handle Thickness | Handle Length | Total Swab Length | Packaging |
|-----------------------|--------------------|-------------------|--------------------|-------------------|-------------------|---------------------|---------------------|--------------------------------------|
| | 12.7mm (0.500") | 4.2mm (0.165") | 25.7mm (1.012") | 5.2mm (0.205") | 3.0mm (0.118") | 101.8mm (4.008") | 127.5mm (5.020") | 20 swabs per bag 50 bags per case |

 

TOC Cleaning Validation Kits

Texwipe's TOC Cleaning Validation Kits are designed to simplify sampling as part of a cleaning validation protocol. The swabs and vials are further cleaned using a proprietary processes to make these kits excellent for use in Total Organic Carbon (TOC) analysis.

The kits are an organized, convenient and secure method for transporting swabs and vials from storage area to sampling sites to laboratory with minimal chance of contamination.

Packaged in cleanroom-compatible, recyclable polypropylene boxes.

Two size options available.



TOC Cleaning Validation Kit

| Product Number | Description | Packaging |
|----------------|--|--------------|
| TX3340 | TOC Cleaning Validation Kit - 12 vials + 24 swabs + 12 labels | 18 kits/case |
| TX3342 | TOC Cleaning Validation Kit, Bulk - 72 vials + 144 swabs + 72 labels | 1 kit/case |

Sterile Available

All Texwipe swabs available in sterile upon request.

Texwipe is certified to ISO 9001 and ISO 13485.



Polyester Swabs

Microdenier Series

Texwipe's Microdenier Swab Series is made from the cleanest microdenier material, 100% polyester, nylon-free. The complete thermal bond construction eliminates adhesive contamination.

Cleanroom laundered, providing ultra low levels of particles, NVRs (non volatile residues) and ions, and engineered to provide enhanced absorbency and quick wicking performance. Streak-free cleaning with scratch-sensitive surfaces and compatible with QAC (quatary ammonium chloride) cleaners and disinfectants. 100% virgin polypropylene handle.


Cleanroom manufactured, made to exacting and consistent tolerances using high-precision automated processes. Lot coded for traceability and quality control.

Packaged in a reclosable, silicone-free bag.



Reclosable, silicone-free bag

| Part No. TX714MD | Head Width | Head Thickness | Head Length | Handle Width | Handle Thickness | Handle Length | Total Swab Length | Packaging |
|-------------------------|--------------------|-------------------|--------------------|-------------------|-------------------|---------------------|---------------------|--------------------------------------|
| | 12.7mm (0.500") | 4.2mm (0.165") | 25.7mm (1.012") | 5.2mm (0.205") | 3.0mm (0.118") | 101.8mm (4.008") | 127.5mm (5.020") | 100 swabs per bag 8 bags per case |

 

| Part No. TX758MD | Head Width | Head Thickness | Head Length | Handle Width | Handle Thickness | Handle Length | Total Swab Length | Packaging |
|-------------------------|-------------------|-------------------|--------------------|-------------------|-------------------|--------------------|--------------------|--------------------------------------|
| | 3.2mm (0.126") | 2.5mm (0.098") | 11.0mm (0.433") | 2.2mm (0.087") | 2.2mm (0.087") | 60.0mm (2.362") | 70.0mm (2.756") | 500 swabs per bag 5 bags per case |








| Part No. TX761MD | Head Width | Head Thickness | Head Length | Handle Width | Handle Thickness | Handle Length | Total Swab Length | Packaging |
|-------------------------|-------------------|-------------------|--------------------|-------------------|-------------------|---------------------|---------------------|--------------------------------------|
| | 6.8mm (0.268") | 3.6mm (0.142") | 16.8mm (0.661") | 3.2mm (0.126") | 3.2mm (0.126") | 145.5mm (5.728") | 162.5mm (6.398") | 100 swabs per bag 8 bags per case |



 Polyester Swabs

Alpha® Series

Texwipe's Alpha® Swab Series is made from the cleanest 100% polyester knit materials with a double layer of fabric for enhanced absorbency. A complete thermal bond construction eliminates adhesive contamination. Cleanroom laundered and manufactured, providing ultra low levels of contaminants. Engineered to resist snagging and abrading. 100% virgin polypropylene handle. Made to exacting, consistent tolerances using high-precision automated processes. Packaged in a silicone-free, amide-free bag.

| Part No. TX714A | Head Width | Head Thickness | Head Length | Handle Width | Handle Thickness | Handle Length | Total Swab Length | Packaging |
|--|--------------------|-------------------|--------------------|-------------------|-------------------|---------------------|---------------------|---|
|  | 12.7mm (0.500") | 4.2mm (0.165") | 25.7mm (1.012") | 5.2mm (0.205") | 3.0mm (0.118") | 101.8mm (4.008") | 127.5mm (5.020") | 100 swabs per bag 2 inner bags of 50 swabs 10 bags per case |
| Part No. TX743B | Head Width | Head Thickness | Head Length | Handle Width | Handle Thickness | Handle Length | Total Swab Length | Packaging |
|  | 4.0mm (0.157") | 3.6mm (0.142") | 12.0mm (0.472") | 3.0mm (0.118") | 3.0mm (0.118") | 58.3mm (2.295") | 70.3mm (2.768") | 500 swabs per bag 5 inner bags of 100 swabs 5 bags per case |
| Part No. TX754B | Head Width | Head Thickness | Head Length | Handle Width | Handle Thickness | Handle Length | Total Swab Length | Packaging |
|  | 3.5mm (0.138") | 3.0mm (0.118") | 9.5mm (0.374") | 2.4mm (0.095") | 2.4mm (0.095") | 60.0mm (2.362") | 69.5mm (2.736") | 500 swabs per bag 5 inner bags of 100 swabs 5 bags per case |
| Part No. TX758B | Head Width | Head Thickness | Head Length | Handle Width | Handle Thickness | Handle Length | Total Swab Length | Packaging |
|  | 3.2mm (0.126") | 2.5mm (0.098") | 11.0mm (0.433") | 2.2mm (0.087") | 2.2mm (0.087") | 60.0mm (2.362") | 70.0mm (2.756") | 500 swabs per bag 5 inner bags of 100 swabs 5 bags per case |
| Part No. TX761 | Head Width | Head Thickness | Head Length | Handle Width | Handle Thickness | Handle Length | Total Swab Length | Packaging |
|  | 6.8mm (0.268") | 2.8mm (0.110") | 16.8mm (0.661") | 3.2mm (0.126") | 3.2mm (0.126") | 145.5mm (5.728") | 162.3mm (6.390") | 100 swabs per bag 10 bags per case |

Absorbond® Series

Texwipe's Absorbond® Swabs Series is made from 100% polyester (hydroentangled) nonwoven material double layer for enhanced absorbency. The complete thermal bond construction eliminates adhesive contamination. Cleanroom processed and manufactured, providing ultra low levels of contamination control. Engineered for use on sensitive surfaces. 100% virgin polypropylene handle. Made to exacting, consistent tolerances using high-precision automated processes. Packaged in a silicone-free, amide-free bag.

| Part No. TX716 | Head Width | Head Thickness | Head Length | Handle Width | Handle Thickness | Handle Length | Total Swab Length | Packaging |
|--|--------------------|-------------------|--------------------|-------------------|-------------------|---------------------|---------------------|---|
|  | 12.7mm (0.500") | 4.2mm (0.165") | 25.7mm (1.012") | 5.2mm (0.205") | 3.0mm (0.118") | 101.8mm (4.008") | 127.5mm (5.020") | 20 swabs per bag 50 bags per case |
| Part No. TX759B | Head Width | Head Thickness | Head Length | Handle Width | Handle Thickness | Handle Length | Total Swab Length | Packaging |
|  | 3.2mm (0.126") | 1.5mm (0.059") | 10.0mm (0.394") | 2.2mm (0.087") | 2.2mm (0.087") | 60.0mm (2.362") | 70.0mm (2.756") | 500 swabs per bag 5 inner bags of 100 swabs 5 bags per case |
| Part No. TX762 | Head Width | Head Thickness | Head Length | Handle Width | Handle Thickness | Handle Length | Total Swab Length | Packaging |
|  | 6.8mm (0.268") | 2.6mm (0.102") | 16.8mm (0.661") | 3.2mm (0.126") | 3.2mm (0.126") | 145.5mm (5.728") | 162.3mm (6.390") | 100 swabs per bag 10 bags per case |

Sterile Available

All Texwipe swabs available in sterile upon request.

Texwipe is certified to ISO 9001 and ISO 13485.

 Texwipe
An ITW Company

| Page 5

CleanFoam® Swabs

CleanFoam® Series A

Texwipe's CleanFoam® Swab Series is made with 100% polyurethane foam, 100 pores per inch, for good chemical compatibility with a variety of solutions. The complete thermal bond construction eliminates adhesive contamination.

100% virgin polypropylene handle. Cleanroom processed and made to exacting, consistent tolerances using high-precision automated processes. Packaged in a silicone-free, amide-free bag.

Foam Series A features 100 swabs per bag.




| Part No. TX706A | Head Width | Head Thickness | Head Length | Handle Width | Handle Thickness | Handle Length | Total Swab Length | Packaging |
|------------------------|--------------------|-------------------|--------------------|-------------------|-------------------|--------------------|--------------------|---|
| | 10.9mm (0.429") | 8.5mm (0.335") | 27.0mm (1.063") | 6.3mm (0.248") | 6.3mm (0.248") | 54.0mm (2.126") | 81.0mm (3.189") | 100 swabs per bag 2 inner bags of 50 swabs 10 bags per case |



| Part No. TX707A | Head Width | Head Thickness | Head Length | Handle Width | Handle Thickness | Handle Length | Total Swab Length | Packaging |
|------------------------|--------------------|-------------------|--------------------|-------------------|-------------------|---------------------|---------------------|---|
| | 15.0mm (0.591") | 8.8mm (0.346") | 25.0mm (0.984") | 6.6mm (0.260") | 3.2mm (0.126") | 106.0mm (4.173") | 131.0mm (5.157") | 100 swabs per bag; 2 inner bags of 50 swabs; 10 bags per case |



| Part No. TX708A | Head Width | Head Thickness | Head Length | Handle Width | Handle Thickness | Handle Length | Total Swab Length | Packaging |
|------------------------|--------------------|-------------------|--------------------|-------------------|-------------------|---------------------|---------------------|---|
| <i>Sterile STX708A</i> | 19.7mm (0.776") | 9.4mm (0.370") | 26.4mm (1.039") | 6.6mm (0.260") | 3.2mm (0.126") | 105.8mm (4.165") | 132.2mm (5.205") | 100 swabs per bag; 2 inner bags of 50 swabs; 10 bags per case |

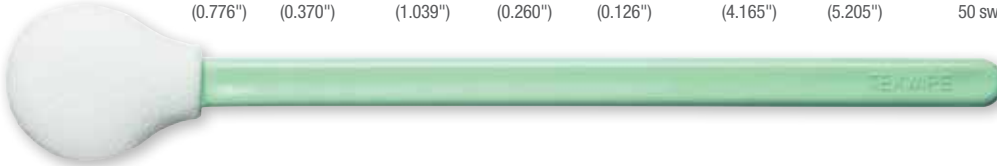

| Part No. TX709A | Head Width | Head Thickness | Head Length | Handle Width | Handle Thickness | Handle Length | Total Swab Length | Packaging |
|------------------------|-------------------|-------------------|--------------------|-------------------|-------------------|--------------------|---------------------|---|
| | 4.8mm (0.189") | 4.2mm (0.165") | 12.0mm (0.472") | 4.3mm (0.169") | 4.3mm (0.169") | 92.5mm (3.642") | 104.0mm (4.094") | 100 swabs per bag 2 inner bags of 50 swabs 10 bags per case |



| Part No. TX710A | Head Width | Head Thickness | Head Length | Handle Width | Handle Thickness | Handle Length | Total Swab Length | Packaging |
|------------------------|-------------------|-------------------|--------------------|-------------------|-------------------|--------------------|---------------------|---|
| | 7.0mm (0.276") | 5.9mm (0.232") | 20.4mm (0.803") | 4.3mm (0.169") | 4.3mm (0.169") | 92.5mm (3.642") | 113.0mm (4.449") | 100 swabs per bag 2 inner bags of 50 swabs 10 bags per case |



| Part No. TX712A | Head Width | Head Thickness | Head Length | Handle Width | Handle Thickness | Handle Length | Total Swab Length | Packaging |
|------------------------|--------------------|-------------------|--------------------|-------------------|-------------------|---------------------|---------------------|---|
| <i>Sterile STX712A</i> | 12.7mm (0.500") | 7.8mm (0.307") | 25.7mm (1.012") | 5.2mm (0.205") | 3.0mm (0.118") | 101.8mm (4.008") | 127.5mm (5.020") | 100 swabs per bag 2 inner bags of 50 swabs 10 bags per case |



CleanFoam® Swabs

CleanFoam® Series B

Texwipe's CleanFoam® Swab Series is made with 100% polyurethane foam, 100 pores per inch, for good chemical compatibility with a variety of solutions. The complete thermal bond construction eliminates adhesive contamination.

100% virgin polypropylene handle. Cleanroom processed and made to exacting, consistent tolerances using high-precision automated processes. Packaged in a silicone-free, amide-free bag.

Foam Series B features 500 swabs per bag.



| Part No. TX740B | Head Width | Head Thickness | Head Length | Handle Width | Handle Thickness | Handle Length | Total Swab Length | Packaging |
|------------------------|-------------------|-------------------|--------------------|-------------------|-------------------|---------------------|---------------------|---|
| | 6.2mm (0.244") | 5.0mm (0.197") | 17.0mm (0.669") | 3.2mm (0.126") | 3.2mm (0.126") | 146.0mm (5.748") | 163.0mm (6.417") | 500 swabs per bag 5 inner bags of 100 swabs 5 bags per case |



| Part No. TX741B | Head Width | Head Thickness | Head Length | Handle Width | Handle Thickness | Handle Length | Total Swab Length | Packaging |
|------------------------|-------------------|-------------------|--------------------|-------------------|-------------------|--------------------|--------------------|---|
| | 3.4mm (0.134") | 3.0mm (0.118") | 10.5mm (0.413") | 2.4mm (0.094") | 2.4mm (0.094") | 56.8mm (2.236") | 67.3mm (2.650") | 500 swabs per bag 5 inner bags of 100 swabs 5 bags per case |



| Part No. TX742B | Head Width | Head Thickness | Head Length | Handle Width | Handle Thickness | Handle Length | Total Swab Length | Packaging |
|------------------------|-------------------|-------------------|--------------------|-------------------|-------------------|--------------------|--------------------|---|
| | 3.6mm (0.142") | 3.5mm (0.138") | 12.0mm (0.472") | 3.0mm (0.118") | 3.0mm (0.118") | 59.0mm (2.323") | 71.0mm (2.795") | 500 swabs per bag 5 inner bags of 100 swabs 5 bags per case |



| Part No. TX751B | Head Width | Head Thickness | Head Length | Handle Width | Handle Thickness | Handle Length | Total Swab Length | Packaging |
|------------------------|-------------------|-------------------|--------------------|-------------------|-------------------|--------------------|--------------------|---|
| | 3.5mm (0.138") | 3.5mm (0.138") | 16.0mm (0.630") | 2.4mm (0.094") | 2.4mm (0.094") | 51.0mm (2.008") | 67.0mm (2.638") | 500 swabs per bag 5 inner bags of 100 swabs 5 bags per case |



| Part No. TX752B | Head Width | Head Thickness | Head Length | Handle Width | Handle Thickness | Handle Length | Total Swab Length | Packaging |
|------------------------|-------------------|-------------------|--------------------|-------------------|-------------------|--------------------|--------------------|---|
| | 3.4mm (0.134") | 3.4mm (0.134") | 20.0mm (0.787") | 2.5mm (0.098") | 2.5mm (0.098") | 50.0mm (1.969") | 70.0mm (2.756") | 500 swabs per bag 5 inner bags of 100 swabs 5 bags per case |



| Part No. TX757B | Head Width | Head Thickness | Head Length | Handle Width | Handle Thickness | Handle Length | Total Swab Length | Packaging |
|------------------------|-------------------|-------------------|--------------------|-------------------|-------------------|--------------------|--------------------|---|
| | 3.2mm (0.126") | 2.6mm (0.102") | 10.0mm (0.395") | 2.2mm (0.087") | 2.2mm (0.087") | 59.7mm (2.350") | 69.7mm (2.744") | 500 swabs per bag 5 inner bags of 100 swabs 5 bags per case |



Sterile Available

All Texwipe swabs available in sterile upon request.

Texwipe is certified to ISO 9001 and ISO 13485.



ESD-Safe Swabs

Texwipe's ESD Swab Series features a Stat-Rite® handle, a patented Inherently Dissipative Polymer, to provide clean ESD protection without contributing particulate contaminants to the process or environment. The complete thermal bond construction eliminates adhesive contamination. Packaged in an anti-static bag.

Available in a choice of CleanFoam®, Alpha® Polyester, or Stick.



CleanFoam® ESD

| Part No. TX750E | Head Width | Head Thickness | Head Length | Handle Width | Handle Thickness | Handle Length | Total Swab Length | Packaging |
|------------------------|-------------------|-------------------|--------------------|-------------------|-------------------|--------------------|--------------------|---|
| | 3.5mm (0.138") | 3.5mm (0.138") | 10.0mm (0.394") | 3.0mm (0.118") | 3.0mm (0.118") | 78.5mm (3.090") | 88.5mm (3.484") | 500 swabs per bag 5 inner bags of 100 swabs 5 bags per case |



| Part No. TX753E | Head Width | Head Thickness | Head Length | Handle Width | Handle Thickness | Handle Length | Total Swab Length | Packaging |
|------------------------|-------------------|-------------------|--------------------|-------------------|-------------------|--------------------|--------------------|---|
| | 3.7mm (0.146") | 3.4mm (0.134") | 10.0mm (0.394") | 3.0mm (0.118") | 3.0mm (0.118") | 80.0mm (3.150") | 90.0mm (3.543") | 500 swabs per bag 5 inner bags of 100 swabs 5 bags per case |



| Part No. TX757E | Head Width | Head Thickness | Head Length | Handle Width | Handle Thickness | Handle Length | Total Swab Length | Packaging |
|------------------------|-------------------|-------------------|--------------------|-------------------|-------------------|--------------------|--------------------|---|
| | 3.8mm (0.150") | 3.4mm (0.134") | 10.0mm (0.394") | 3.0mm (0.118") | 3.0mm (0.118") | 80.7mm (3.177") | 90.7mm (3.571") | 500 swabs per bag 5 inner bags of 100 swabs 5 bags per case |



Alpha® Polyester ESD

| Part No. TX758E | Head Width | Head Thickness | Head Length | Handle Width | Handle Thickness | Handle Length | Total Swab Length | Packaging |
|------------------------|-------------------|-------------------|--------------------|-------------------|-------------------|--------------------|--------------------|---|
| | 4.0mm (0.157") | 3.0mm (0.118") | 10.0mm (0.394") | 3.0mm (0.118") | 3.0mm (0.118") | 80.5mm (3.169") | 90.5mm (3.563") | 500 swabs per bag 5 inner bags of 100 swabs 5 bags per case |



| Part No. TX761D | Head Width | Head Thickness | Head Length | Handle Width | Handle Thickness | Handle Length | Total Swab Length | Packaging |
|------------------------|-------------------|-------------------|--------------------|-------------------|-------------------|---------------------|---------------------|---------------------------------------|
| | 6.8mm (0.268") | 4.0mm (0.157") | 17.0mm (0.669") | 3.0mm (0.118") | 3.0mm (0.118") | 147.0mm (5.787") | 164.0mm (6.457") | 100 swabs per bag 10 bags per case |



Stick ESD

| Part No. TX769E | Head Width | Head Thickness | Head Length | Handle Width | Handle Thickness | Handle Length | Total Swab Length | Packaging |
|------------------------|-------------------|-------------------|-------------------|-------------------|-------------------|--------------------|--------------------|---|
| | 1.0mm (0.039") | 1.0mm (0.039") | 9.6mm (0.378") | 2.4mm (0.094") | 2.4mm (0.094") | 56.5mm (2.224") | 66.1mm (2.602") | 500 swabs per bag 5 inner bags of 100 swabs 5 bags per case |



Cotton Swabs

Texwipe's Cotton and Cotton/Foam Swab Series is designed to maximize the characteristics of cotton. Available in 100% cotton or cotton/polyurethane foam. These swabs are bonded securely to a wooden shaft by an aqueous-based adhesive.

| Part No. TX700B | Head Width | Head Thickness | Head Length | Handle Width | Handle Thickness | Handle Length | Total Swab Length | Packaging |
|------------------------|--------------------|--------------------|--------------------|-------------------|-------------------|---------------------|---------------------|---|
| | 13.5mm (0.531") | 13.5mm (0.531") | 28.0mm (1.102") | 2.5mm (0.098") | 2.5mm (0.098") | 126.0mm (4.961") | 154.0mm (6.063") | 500 swabs per bag 10 inner bags of 50 swabs 5 bags per case |



| Part No. TX705 | Head Width | Head Thickness | Head Length | Handle Width | Handle Thickness | Handle Length | Total Swab Length | Packaging |
|-----------------------|-------------------|-------------------|--------------------|-------------------|-------------------|---------------------|---------------------|--|
| | 7.0mm (0.276") | 7.0mm (0.276") | 17.0mm (0.669") | 2.5mm (0.098") | 2.5mm (0.098") | 135.0mm (5.315") | 152.0mm (5.984") | 1,000 swabs per bag 10 inner bags of 100 swabs 5 bags per case |



| Part No. TX720B | Head Width | Head Thickness | Head Length | Handle Width | Handle Thickness | Handle Length | Total Swab Length | Packaging |
|------------------------|--------------------|--------------------|--------------------|-------------------|-------------------|---------------------|---------------------|---|
| | 11.8mm (0.465") | 10.0mm (0.394") | 26.3mm (1.035") | 2.5mm (0.098") | 2.5mm (0.098") | 127.0mm (5.000") | 154.0mm (6.063") | 500 swabs per bag 10 inner bags of 50 swabs 5 bags per case |



Specialty Swabs & Tools

TX726 is our innovative CrushTube Swab, featuring 91% IPA in an enclosed tube. Packaged in a resealable bag.

| Part No. TX726 | Head Width | Head Thickness | Head Length | Handle Width | Handle Thickness | Handle Length | Total Swab Length | Packaging |
|-----------------------|-------------------|----------------|--------------------|------------------|------------------|-------------------|-------------------|---------------------------------------|
| | 8.3mm (0.327") | n/a | 10.0mm (0.394") | 9.5mm (0.37") | 9.5mm (0.37") | 44.0mm (1.73") | 47.6mm (1.89") | 50 swabs per box 10 boxes per case |



TX730 is a 100% nylon swab with micro bristles that grab particles or remove liquids by capillary forces. Ideal for tight spaces. Packaged in a silicone-free, amide-free bag.

| Part No. TX730 | Head Width | Head Thickness | Head Length | Handle Width | Handle Thickness | Handle Length | Total Swab Length | Packaging |
|-----------------------|-------------------|-------------------|--------------------|-------------------|-------------------|---------------------|---------------------|--------------------------------------|
| | 0.8mm (0.031") | 0.8mm (0.031") | 15.5mm (0.610") | 2.8mm (0.110") | 2.8mm (0.110") | 152.5mm (6.004") | 168.0mm (6.614") | 50 swabs per bag 10 bags per case |



Sterile Available

All Texwipe swabs available in sterile upon request.

Texwipe is certified to ISO 9001 and ISO 13485.



General Purpose Swabs

Texwipe's General Purpose Swab Series is designed for those customers needing a swab in industrial or general purpose applications. 100% polypropylene handle provides excellent chemical compatibility. Complete thermal bond construction eliminates adhesive contamination.

Packaged in a reclosable, silicone-free bag. Available in Polyester Honeycomb and Foam.



Reclosable, silicone-free bag

Polyester Honeycomb

Texwipe's General Purpose Polyester Swab Series, made with 100% polyester, was engineered with a honeycomb-type cell designed to maximize absorbency and capture of large particles and dirt in less critical areas.

| Part No. TX801 | Head Width | Head Thickness | Head Length | Handle Width | Handle Thickness | Handle Length | Total Swab Length | Packaging |
|-----------------------|--------------------|-------------------|--------------------|-------------------|-------------------|---------------------|---------------------|--------------------------------------|
| | 13.5mm (0.531") | 3.5mm (0.138") | 25.2mm (0.992") | 5.2mm (0.205") | 3.0mm (0.118") | 102.3mm (4.028") | 127.5mm (5.020") | 100 swabs per bag 6 bags per case |



| Part No. TX802 | Head Width | Head Thickness | Head Length | Handle Width | Handle Thickness | Handle Length | Total Swab Length | Packaging |
|-----------------------|-------------------|-------------------|-------------------|-------------------|-------------------|--------------------|--------------------|--------------------------------------|
| | 3.5mm (0.138") | 3.0mm (0.118") | 9.2mm (0.362") | 2.5mm (0.098") | 2.5mm (0.098") | 60.0mm (2.362") | 69.2mm (2.724") | 500 swabs per bag 5 bags per case |



General Purpose Swabs



Reclosable, silicone-free bag

Foam

Texwipe's General Purpose Foam Swab Series, made with 100% polyurethane foam, was engineered for applying and absorbing adhesives, greases and liquids in less critical areas.


| Part No. TX803 | Head Width | Head Thickness | Head Length | Handle Width | Handle Thickness | Handle Length | Total Swab Length | Packaging |
|-----------------------|-------------------|-------------------|--------------------|-------------------|-------------------|--------------------|--------------------|--------------------------------------|
| | 3.6mm (0.142") | 3.5mm (0.138") | 12.0mm (0.472") | 3.0mm (0.118") | 3.0mm (0.118") | 59.0mm (2.323") | 71.0mm (2.795") | 500 swabs per bag 3 bags per case |



| Part No. TX804 | Head Width | Head Thickness | Head Length | Handle Width | Handle Thickness | Handle Length | Total Swab Length | Packaging |
|-----------------------|-------------------|-------------------|--------------------|-------------------|-------------------|--------------------|--------------------|--------------------------------------|
| | 3.5mm (0.138") | 3.5mm (0.138") | 15.5mm (0.610") | 2.4mm (0.094") | 2.4mm (0.094") | 51.0mm (2.008") | 66.5mm (2.619") | 500 swabs per bag 3 bags per case |



| Part No. TX805 | Head Width | Head Thickness | Head Length | Handle Width | Handle Thickness | Handle Length | Total Swab Length | Packaging |
|-----------------------|--------------------|-------------------|--------------------|-------------------|-------------------|---------------------|---------------------|-------------------------------------|
| | 19.7mm (0.776") | 9.4mm (0.370") | 26.4mm (1.039") | 6.6mm (0.260") | 3.2mm (0.126") | 105.8mm (4.165") | 132.2mm (5.205") | 80 swabs per bag 5 bags per case |

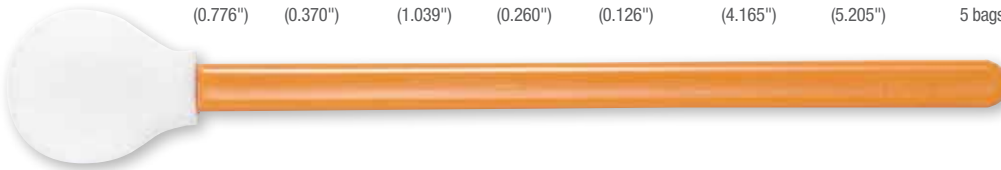

Swab Solvent Compatibility


| Solvent | Head Substrate | | Handle Material | |
|-----------------------|----------------|-----------|-----------------|------------|
| | Foam | Polyester | Polypropylene | Stat-Rite® |
| Acetic Acid | U | U | | |
| Acetone | S | U | U | D |
| Acetonitrile | U | U | U | D |
| Ammonia, Anhydrous | S | U | | |
| Aniline | S | U | | |
| Benzene | S | U | U | D |
| Carbon Tetrachloride | S | U | | |
| Chloroform | S | U | | |
| Chlorophenol | D | D | | |
| Chromic Acid | D | D | | |
| Cyclohexane | S | U | | |
| Dimethylformamide | D | S | | |
| Dimethylsulfoxide | D | S | | |
| Ethyl Acetate | S | U | | |
| Ethyl Alcohol | U | U | | |
| Ethyl Chloride | S | U | | |
| Formic Acid | D | U | | |
| Hexane | U | U | U | U |
| Hydrochloric Acid 48% | D | D | U | U |
| Hydrogen Peroxide | D | U | | |
| Isopropyl Alcohol | U | U | U | U |
| Methanol | S | U | U | U |
| Methyl Ethyl Ketone | S | U | | |
| Methylene Chloride | S | U | U | D |
| Nitric Acid 100% | D | D | U | D |
| Nitrobenzene | S | U | | |
| Perchloroethylene | U | U | | |
| Phosphoric Acid 85% | D | U | | |
| Sodium Hydroxide 36% | S | U | | |
| Sulfuric Acid 98% | D | D | | |
| Toluene | S | U | U | D |
| Trichloroethylene | S | U | | |
| Vinyl Acetate | S | U | | |
| Water | U | U | U | U |
| Xylene | S | U | U | D |

Compatibility is determined at room temperature.


Key: D – Degrades; S – Swells, U – Unaffected

Swab Index

| | |
|-------------------|-------|
| STX705P | Pg. 2 |
| STX705W | Pg. 2 |
| STX708A | Pg. 2 |
| STX712A | Pg. 2 |
| STX764 | Pg. 2 |
| STX763 | Pg. 2 |
| TX700B | Pg. 7 |
| TX705 | Pg. 7 |
| TX706A | Pg. 4 |
| TX707A | Pg. 4 |
| TX708A | Pg. 4 |
| TX709A | Pg. 4 |
| TX710A | Pg. 4 |
| TX712A | Pg. 4 |
| TX714A | Pg. 3 |
| TX714K | Pg. 1 |
| TX714MD | Pg. 2 |
| TX715 | Pg. 1 |
| TX716 | Pg. 3 |
| TX720B | Pg. 7 |
| TX726 | Pg. 7 |
| TX730 | Pg. 7 |
| TX740B | Pg. 5 |
| TX741B | Pg. 5 |
| TX742B | Pg. 5 |
| TX743B | Pg. 3 |
| TX750E | Pg. 6 |
| TX751B | Pg. 5 |
| TX752B | Pg. 5 |
| TX753E | Pg. 6 |
| TX754B | Pg. 3 |
| TX757B | Pg. 3 |
| TX757E | Pg. 6 |
| TX758B | Pg. 3 |
| TX758E | Pg. 6 |
| TX759B | Pg. 3 |
| TX761K | Pg. 1 |
| TX758MD | Pg. 2 |
| TX761 | Pg. 3 |
| TX761D | Pg. 6 |
| TX761MD | Pg. 2 |
| TX762 | Pg. 3 |
| TX769E | Pg. 6 |
| TX801 | Pg. 8 |
| TX802 | Pg. 8 |
| TX803 | Pg. 8 |
| TX804 | Pg. 8 |
| TX805 | Pg. 8 |

 

Wipers

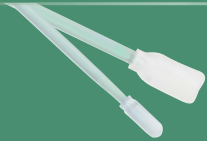

Swabs



 
Mops

Disinfectants



Solutions

Stationery



Mats

Sterile



www.texwipe.com

Distributed in Australia and New Zealand by:

ThermoFisher
SCIENTIFIC

Australia: For customer service, call 1300-735-292

Visit us online at: www.thermofisher.com.au

New Zealand: For customer service, call 0800-933-966

Visit us online at: www.thermofisher.co.nz

©2015 Thermo Fisher Scientific Inc. All rights reserved.

 **Texwipe**[®]
An  Company

Texwipe Americas +1 336 996 7046
Texwipe Europe +31 88 1307 410
Texwipe Asia +63 049 530 3390
Texwipe China +65 6468 9433

www.texwipe.com