

# Full-extraction control for confident SARS-CoV-2 testing

Monitor novel coronavirus testing with the new positive control

The **Thermo Scientific™ AcroMetrix™ SARS-CoV-2 Control (RUO)** is a full-process qualitative control suitable for daily runs and lot-to-lot verification. Containing positive reference material, you can treat it just like a clinical sample to ensure high-quality results in your lab.



#### Mimics clinical specimen

Full extraction possible with **inactivated virus** in a **proprietary buffer**



#### Supports fully automated workflows

Excellent **compatibility** with existing **SARS-CoV-2 assays** on the market

Maximize usage of each vial

**12** months  
**shelf life**

@ -20 °C  
or below



up to **5**  
**freeze-  
thaws**




**1** month  
**open-vial  
stability**

@ 2-8 °C



## Thermo Scientific AcroMetrix SARS-CoV-2 Control

Catalog number	Product name	Control	Quantity
954517	AcroMetrix SARS-CoV-2 Control	Positive	5 x 1.5 mL

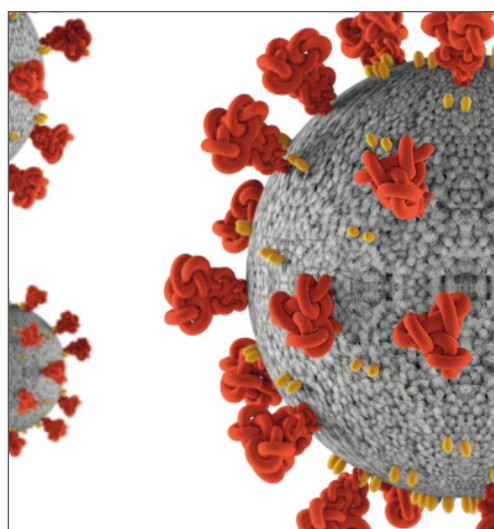

## Start COVID-19 QC at the amplification step

### Thermo Scientific AcroMetrix COVID-19 RNA Control

Catalog Number: 954519

- Full-length genomic RNA
- Low-positive and ultra-low-positive concentrations

Find out more at: [thermofisher.com/covid-19-control](https://thermofisher.com/covid-19-control)

### Customer Support

**Phone:** 1-800-232-3342 - Press 1 for Customer Service, then 3 for QC

**Fax:** 1-800-829-8115

**e-mail:** [mgc-masorders@thermofisher.com](mailto:mgc-masorders@thermofisher.com)

### Sales Support

**Phone:** 1-800-232-3342

**e-mail:** [sales.diagnostics.fmt@thermofisher.com](mailto:sales.diagnostics.fmt@thermofisher.com)

### Technical Service and Support

**Phone:** 1-800-232-3342- option 2, then 2 for QC

### Clinical Diagnostics

#### USA

46500 Kato Road  
Fremont, CA 94538 USA  
Tel. 800-232-3342 / + 1 510-979-5000  
[sales.diagnostics.fmt@thermofisher.com](mailto:sales.diagnostics.fmt@thermofisher.com)

#### Asia Pacific

Tel: +65 6499 9999  
[cdd.asia.info2@thermofisher.com](mailto:cdd.asia.info2@thermofisher.com)

#### Australia

Tel. + 61 1800 333 110  
[auinfo@thermofisher.com](mailto:auinfo@thermofisher.com)

#### Canada

Tel. 905-286-4290  
[CDD.Canada@thermofisher.com](mailto:CDD.Canada@thermofisher.com)

#### China

Tel. +86 400 650 5118  
[sales.china@thermofisher.com](mailto:sales.china@thermofisher.com)

#### France, Belgium (Brussels / Wallonia) & Luxembourg

Tel. + 33 (0) 1 40 86 65 00  
[cdx.fr.info@thermofisher.com](mailto:cdx.fr.info@thermofisher.com)

#### Germany

Tel. +49 (0) 3302 883 608  
[cdx.de.info@thermofisher.com](mailto:cdx.de.info@thermofisher.com)

#### Hong Kong

Tel. Tel. + 852 3107 7600  
[sales.hk@thermofisher.com](mailto:sales.hk@thermofisher.com)

#### Italy

[distributor.cdd@thermofisher.com](mailto:distributor.cdd@thermofisher.com)

#### Japan

Tel. + 81 (0) 120 489 211  
[JPYOK-CDD.QC@thermofisher.com](mailto:JPYOK-CDD.QC@thermofisher.com)

#### Netherlands & Belgium (Flemish)

Tel. +49 3302 883 660  
[Info.benelux.cdd@thermofisher.com](mailto:Info.benelux.cdd@thermofisher.com)

#### New Zealand

Tel. + 61 0800933 966  
[nzinfo@thermofisher.co.nz](mailto:nzinfo@thermofisher.co.nz)

#### Nordic

Tel. + 46 8 594 691 30  
[info.nordic.cdd@thermofisher.com](mailto:info.nordic.cdd@thermofisher.com)

#### Russia

Tel. + 7 495 739 76 41  
[info.btd.moscow@thermofisher.com](mailto:info.btd.moscow@thermofisher.com)

#### South Africa

Tel. +27 11 792 6790  
[support-za.idd@thermofisher.com](mailto:support-za.idd@thermofisher.com)

#### Spain & Portugal (Iberia)

Tel. + 34 93589 8338  
[CDD.Info.ES@thermofisher.com](mailto:CDD.Info.ES@thermofisher.com)

#### Switzerland & Austria

Tel. + 41 26 663 86 70  
[cdx.ch.info@thermofisher.com](mailto:cdx.ch.info@thermofisher.com)

#### United Kingdom & Ireland

Tel. + 44 1442 868 940  
[cdx.UK.info@thermofisher.com](mailto:cdx.UK.info@thermofisher.com)

#### For Countries Not Listed

[distributor.cdd@thermofisher.com](mailto:distributor.cdd@thermofisher.com)

Find out more at [thermofisher.com/954517](https://thermofisher.com/954517)

Availability of product in each country depends on local regulatory marketing authorization status.