

Time to standardize BCR-ABL validation

The Thermo Scientific™ AcroMetrix™ BCR-ABL Panel is the world's first external full-process control solution for the analytical evaluation of BCR-ABL test methods. Thanks to expanded dynamic range, you can now monitor assay performance at every clinical stage with greater confidence using a highly characterized product.



Full-process BCR-ABL control panel

Validate assay performance at every stage of sample processing:

The AcroMetrix BCR-ABL Panel ensures commutability by using cells to mimic patient specimen and therefore can be processed the same way as your clinical samples.



Aligned with the WHO standard

Achieve highly accurate result measurements: The AcroMetrix BCR-ABL Panel is traceable to the World Health Organization's first International Genetic Reference Panel for quantitation of BCR-ABL translocation by RQ-PCR, NIBSC Code: 09/138.



Sensitive even at MR* 4.5

Empower clinicians to make informed therapy decisions: The AcroMetrix BCR-ABL Panel offers a dynamic range from 10% to 0.0032%, allowing your lab to analytically validate an extended reportable range for your assay down to the lowest level of molecular response (MR).


* MR = molecular response

NEW

Unique third-party control for
monitoring BCR-ABL assays

WORLD'S **1st**

ThermoFisher
SCIENTIFIC

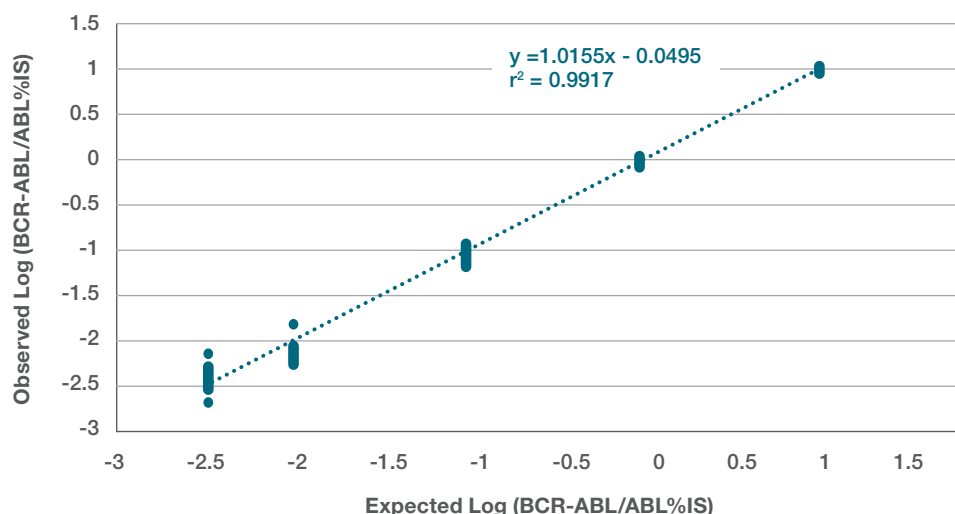

Great linearity across the MR* range

Thermo Scientific AcroMetrix BCR-ABL Panel (Part number: 956980)

Components Names	MR* Level	Quantity per Kit
AcroMetrix BCR-ABL Panel A (10%)	MR 1.0	1 x 0.5 mL
AcroMetrix BCR-ABL Panel B (1%)	MR 2.0	1 x 0.5 mL
AcroMetrix BCR-ABL Panel C (0.1%)	MR 3.0	1 x 0.5 mL
AcroMetrix BCR-ABL Panel D (0.01%)	MR 4.0	1 x 0.5 mL
AcroMetrix BCR-ABL Panel E (0.0032%)	MR 4.5	1 x 0.5 mL

* MR = molecular response



Customer Support

Phone: 1-800-232-3342 - Press 1 for Customer Service, then 3 for QC

Fax: 1-800-829-8115

e-mail: mgc-masorders@thermofisher.com

Sales Support

Phone: 1-800-232-3342

e-mail: sales.diagnostics.fmt@thermofisher.com

Technical Service and Support

Phone: 1-800-232-3342- option 2, then 2 for QC

Clinical Diagnostics

USA
46500 Kato Road
Fremont, CA 94538 USA
Tel. 800-232-3342 / + 1 510-979-5000
sales.diagnostics.fmt@thermofisher.com

Asia Pacific
Tel: +65 6499 9999
cdd.asia.info@thermofisher.com

Australia
Tel. + 61 1800 333 110
auinfo@thermofisher.com

Canada
Tel. 905-286-4290
CDD.Canada@thermofisher.com

China
Tel. +86 400 650 5118
sales.china@thermofisher.com

France, Belgium (Brussels / Wallonia) & Luxembourg
Tel. + 33 (0) 1 40 86 65 00
cdx.fr.info@thermofisher.com

Germany
Tel. +49 (0) 3302 883 608
cdx.de.info@thermofisher.com

Hong Kong
Tel. + 852 3107 7600
sales.hk@thermofisher.com

Italy
distributor.cdd@thermofisher.com

Japan
Tel. + 81 (0)120-147-075
JPYOK-CDD.QC@thermofisher.com

Netherlands & Belgium (Flemish)
Tel. +49 3302 883 660
Info.benelux.cdd@thermofisher.com

New Zealand
Tel. + 61 0800933 966
nzinfo@thermofisher.co.nz

Nordic
Tel. + 46 8 594 691 30
info.nordic.cdd@thermofisher.com

Russia
Tel. + 7 495 739 76 41
info.btd.moscow@thermofisher.com

South Africa
Tel. +27 11 792 6790
support-za.idd@thermofisher.com

Spain & Portugal (Iberia)
Tel. + 34 93589 8338
CDD.Info.ES@thermofisher.com

Switzerland & Austria
Tel. + 41 26 663 86 70
cdx.ch.info@thermofisher.com

United Kingdom & Ireland
Tel. + 44 1442 868 940
cdx.UK.info@thermofisher.com

For Countries Not Listed
distributor.cdd@thermofisher.com

Find out more at thermofisher.com/acrometrix

Availability of product in each country depends on local regulatory marketing authorization status.

©2019 Thermo Fisher Scientific Inc. All rights reserved. All trademarks are the property of Thermo Fisher Scientific and its subsidiaries. **FR-MTL-0152-AcroMetrix-BCR-ABL-Flyer**

ThermoFisher
SCIENTIFIC