


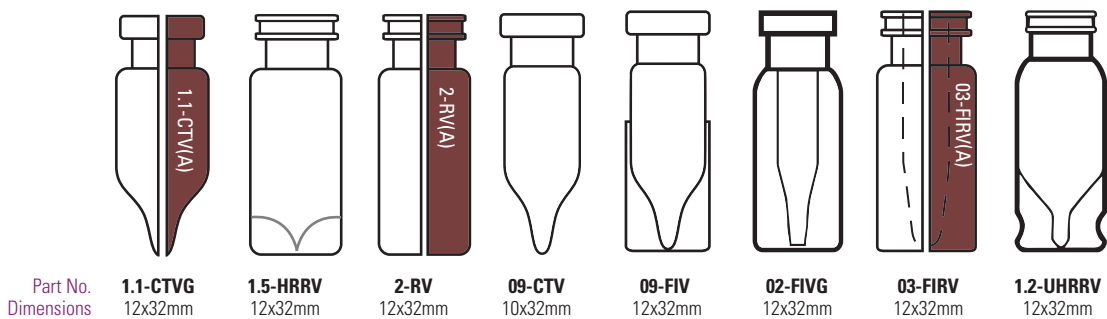
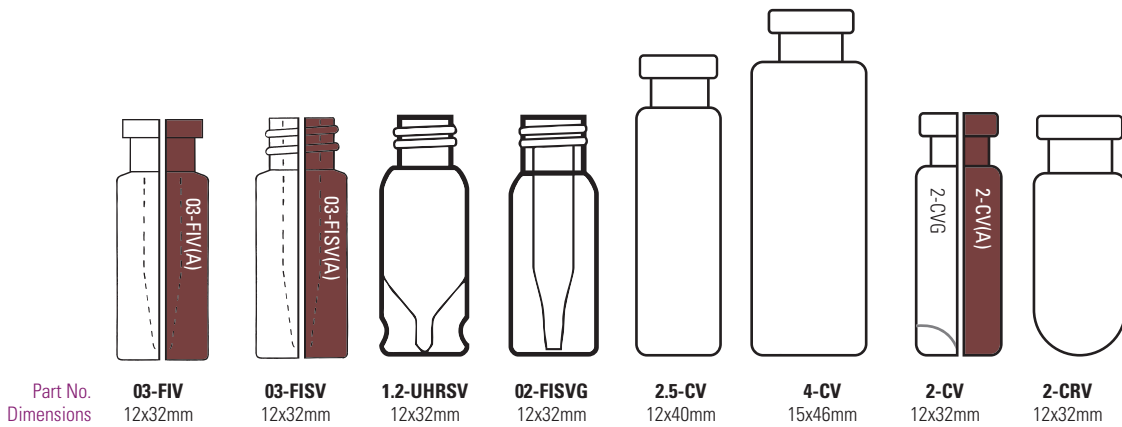


# Chromacol Vial Comparison Chart

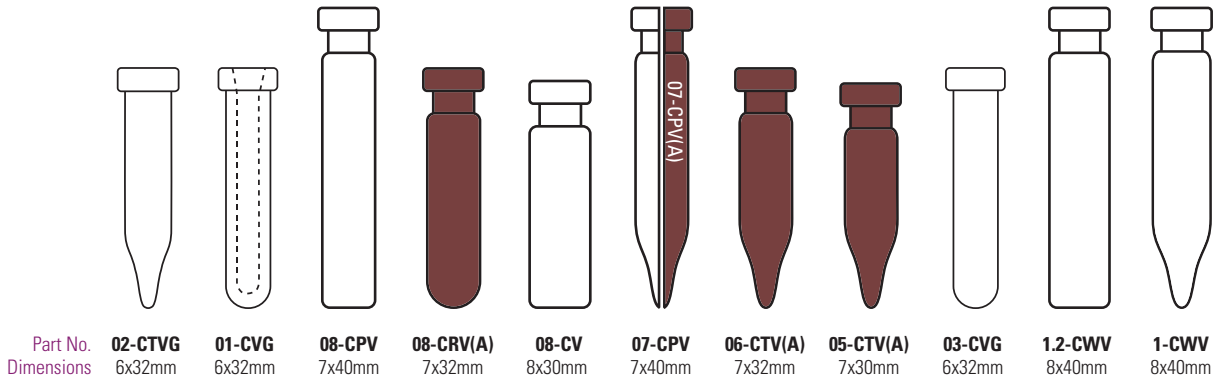

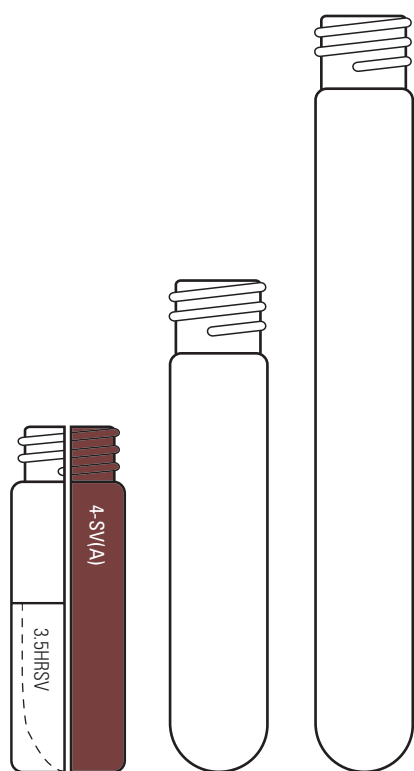

Part No. Dimensions  
**4-SV** 15x46mm  
**5-SV** 13x65mm  
**10-SV** 13x100mm

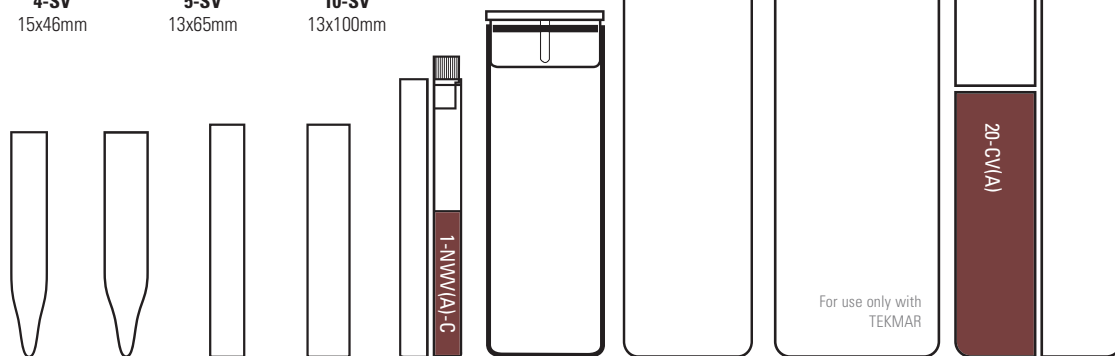

Part No. Dimensions  
**02-MTV** 5x30mm  
**02-MTVVG** 6x30mm  
**02-NV** 5x31mm  
**03-NV** 6x31mm  
**1-NWV** 8x40mm  
**4-NWV-C** 15x46mm  
**12-CV** 18x65mm  
**22-CV** 22x75mm  
**20-CV/20-HSV** 22x75mm



Part No. Dimensions  
**9-CV** 18x50mm  
**6-CV** 22x38mm  
**20-EPSVCA** 27x57mm  
**27-CV** 30x60mm  
**10-CV/10-HSV** 22x45mm

# Chromacol Caps and Septa Comparison Chart

Part No. Dimensions	 <b>*8-AC6</b> 8x5mm	 <b>8-AC7</b> 8x5mm	 <b>8-ACB</b> 8x5mm	 <b>8-AC-CBT1</b> 8x5mm	 <b>8-AC-ST15</b> 8x5mm	 <b>8-AC-ST101</b> 8x5mm	 <b>8-AC-ST101X</b> 8x5mm	 <b>8-AC(B)-ST144</b> 8x5mm	
Part No. Dimensions	 <b>8-ACT</b> 8x5mm	 <b>8-AC-TST1</b> 8x5mm	 <b>8-PEC1</b> 8x5mm	 <b>8-PEC1X</b> 8x5mm	 <b>*8-SC</b> 8x9mm	 <b>*8-SCJ</b> 8x9mm	 <b>8-SC-8RT1</b> 8x9mm	 <b>8-SC-ST15</b> 8x9mm	
Part No. Dimensions	 <b>8-ST14</b> 8x1.4mm	 <b>8-ST14X</b> 8x1.4mm	 <b>8-ST143</b> 8x1.5mm	 <b>8-ST144</b> 8x1.4mm	 <b>8-6RT1</b> 8x1mm	 <b>8-ST101</b> 8x1mm	 <b>8-T02</b> 8x0.25mm	 <b>8-TST1</b> 8x1mm	 <b>8-ST15</b> 8x1.5mm
Part No. Dimensions	 <b>9-MS(BG)-ST1</b> 9x6.5mm	 <b>*9-SCK(B)-8RT1</b> 9x6.5mm	 <b>9-SCK(B)-ST101</b> 9x6.5mm	 <b>*9-SCK(B)-ST1</b> 9x6.5mm	 <b>9-SCK(B)-TST1</b> 9x6.5mm	 <b>9-SCSK-8RT1</b> 9x6.5mm	 <b>9-SCJ(W)-ST101</b> 12.9x7.9mm	 <b>*11-AC6</b> 11x6mm	
Part No. Dimensions	 <b>*11-AC7</b> 11x6mm	 <b>11-ACB</b> 11x6mm	 <b>11-AC-CBT1</b> 11x6mm	 <b>11-AC-ST101</b> 11x6mm	 <b>11-AC-ST101X</b> 11x6mm	 <b>11-AC(B)-ST144</b> 11x6mm	 <b>11-AC-ST15</b> 11x6mm	 <b>11-ACT</b> 11x6mm	
Part No. Dimensions	 <b>11-AC-TST1</b> 11x6mm	 <b>11-LLX</b> 11x3mm	 <b>11-PEC1</b> 11x6mm	 <b>11-PEC1X</b> 11x6mm	 <b>11-PEC-ST1</b> 11x7mm	 <b>11-MC-ST15</b>	 <b>11-MC-8RT1</b>	 <b>11-MC-ST101</b>	

\* Cap available in alternative colors. See below for more details

## Alternative Colors

### 8-AC6

-  8-AC6(R)
-  8-AC6(B)




### 8-SC

-  8-SC(R)
-  8-SC(W)






### 8-SCJ

-  8-SCJ(W)


### 9-SCK(B)-8RT1

-  9-SCK(G)-8RT1
-  9-SCK(N)-8RT1
-  9-SCK(B)-8RT1X

### 9-SCK(B)-ST1

 
 

 
 
 
 














 
 



 
 

 
 












-  9-SCK(G)-ST1
-  9-SCK(N)-ST1
-  9-SCK(B)-ST1X
-  9-SC(BLK)-BST1
-  9-SC(GY)-BST1X

### 11-AC6

-  11-AC6(R)

### 11-AC7

-  11-AC7(R)
-  11-AC7(GO)
-  11-AC7(G)
-  11-AC7(B)

Part No. Dimensions	 <b>11-PSN(B)</b> 11x6.5mm	 <b>11-PSN(B)-ST101</b> 11x6.5mm	 <b>*11-PSN(B)-T02</b> 11x6.5mm	 <b>11-PSN(B)-TST1</b> 11x6.5mm	 <b>11-PSN(B)-8RT1</b> 11x6.5mm	 <b>*11-PSN(B)-ST1X</b> 11x6.5mm	 <b>11-PSN(B)-ST1</b> 11x6.5mm
Part No. Dimensions	 <b>*12-SC</b> 12x10mm	 <b>12-SCS</b> 12x10mm	 <b>12-SC-ST2</b> 12x10mm	 <b>12-SC-8RT1</b> 12x10mm	 <b>13-SC-ST15</b> 12x10mm	 <b>13-SCST</b> 12x10mm	
Part No. Dimensions	 <b>12-ST2</b> 12x2mm	 <b>12-ST18</b> 12x1.8mm	 <b>12-6RT1</b> 12x1mm	 <b>12-ST101</b> 12x1mm	 <b>12-T02</b> 12x0.25mm	 <b>8-NPWP</b> 8x9mm	 <b>12-NPEP4</b> 12x7mm
Part No. Dimensions	 <b>18-MSC</b> 18x13mm	 <b>18-MSC-CBT3</b> 18x13mm	 <b>18-MSC-ST201</b> 18x13mm	 <b>20-ACB</b> 20x7mm	 <b>20-MCB</b> 20x7mm	 <b>*20-MCBC</b> 20x7mm	
Part No. Dimensions	 <b>20-MCBC(R)-CBT3</b>	 <b>*20-MCBC-ST3</b> 20x7mm	 <b>20-AC-CBT3</b> 20x7mm	 <b>20-AC-ST3</b> 20x7mm	 <b>20-CB3</b> 20x3mm	 <b>20-CBT3</b> 20x3mm	
Part No. Dimensions	 <b>20-CBT3B</b> 20x3mm	 <b>20-ASH3</b> 20x1.5mm	 <b>20-LLX</b> 20x3mm	 <b>20-ST3</b> 20x3mm	 <b>20-ST3HT</b> 20x3.1mm	 <b>20-ST15</b> 20x1.5mm	
Part No. Dimensions	 <b>20-ST101</b> 20x1mm	 <b>18-ST101</b> 18x1mm	 <b>20-B3P</b> 20x9mm	 <b>20-2FB3</b> 20x13.4mm	 <b>20-PEPC5</b> 20x10mm		

\* Cap available in alternative colors. See below for more details

### Alternative Colors

#### 11-PSN(B)-T02

■ 11-PSN(R)-T02

#### 11-PSN(B)-ST1X

■ 11-PSN(G)-ST1X

#### 12-SC

■ 12- SC(R)

□ 12- SC(W)

■ 12- SC(Y)

#### 20-MCBC

■ 20-MCBC(R)

#### 20-MCBC-ST3

■ 20-MCBC(R)-ST3

□ 20-MCBC(N)-ST3