

MEET YOUR FLUCTUATING COVID-19 TESTING NEEDS CONFIDENTLY AND EFFICIENTLY

AN EVOLVING CHALLENGE, A SCALABLE SOLUTION



THERMO FISHER SCIENTIFIC™ AMPLITUDE™ SOLUTION

1

SOURCE FOR SECURED ASSAY SUPPLY

4

EMPLOYEE OPERATION

1K-8K

TEST RESULTS PER DAY

24/7

PRIORITY SUPPORT*



PEACE OF MIND IN AN OFTEN
CHAOTIC LABORATORY
TESTING ENVIRONMENT



TURNKEY TECHNOLOGY


50%

OF COVID-19 TESTING
IS PERFORMED ON
TECHNOLOGY FROM
THERMO FISHER SCIENTIFIC

APPLIED BIOSYSTEMS™ TAQPATH™ COVID-19
HIGH-THROUGHPUT COMBO KIT



ACCURATE, PROVEN,
GOLD-STANDARD TECHNOLOGY

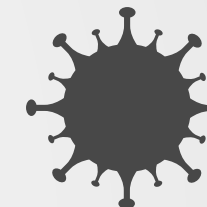

USES A MULTI-TARGET DESIGN
TO COMPENSATE FOR EMERGING
SARS-CoV-2 VARIANTS AND
MUTATIONS



CAN SIGNAL THE PRESENCE OF THE S GENE
69-70DEL MUTATION AND, POTENTIALLY, OF
THE B.1.1.7 (UK) VARIANT

* 365-day, 24/7 priority technical support is available in the English language only. Rapid-response on-site support within 24 hours is subject to regional availability. Regulatory requirements vary by country; products may not be available in your geographic area.

Learn more about the Amplitude Solution at thermofisher.com/amplitude

ThermoFisher
SCIENTIFIC

For Emergency Use Authorization (EUA) Only. For Prescription Use Only. For *In Vitro* Diagnostic Use. © 2021 Thermo Fisher Scientific Inc. All rights reserved. All trademarks are the property of Thermo Fisher Scientific and its subsidiaries unless otherwise specified. COL114286 0421