


# Balanced sample protection

**LOWEST  
ENERGY**

**TIGHT PEAK  
VARIATION**

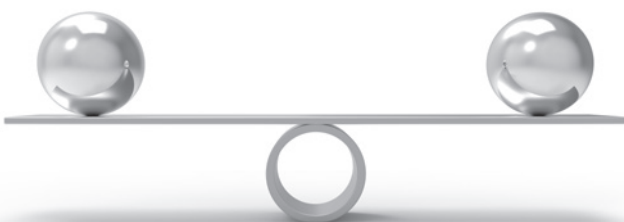

Thermo Scientific™ TSX Series Ultra-Low Freezers are designed to meet the highest protection and sustainability standards:

**Best peak variation of energy-efficient ultra-low freezers:**

~+4.4/-0.4°C

**Low energy usage:** as low as 7.9 kWh/day

**Best overall temperature uniformity of energy-efficient**

**ULT freezers:** less than 5.2°C with door openings; less than 4°C without door openings<sup>1</sup>

**0.85°C steady-state temperature** variation over time

**Longest warm-up time** from -80°C to -50°C: 5.05 hours<sup>2</sup>

**Industry leading standard warranty:** 2 years parts and labor;  
7 years compressor parts

Now through December 31, 2017

## SAVE UP TO 46%


on TSX Series freezers or TSX freezers with Nalgene™ boxes and Nunc™ tubes.

See the reverse side for details.



# SAVE UP TO 46% on Thermo Scientific TSX Series Ultra Low Freezer Packages with Racks, Nalgene Boxes and Nunc Cryo Vials

**Purchase these freezers with racks, boxes and vials!**

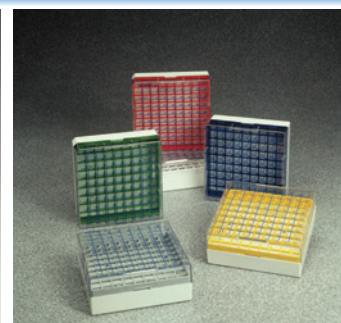

Model No.	Package Includes	Price
TSX40086APBRTSP	TSX400 19.4 cu. ft. freezer, 115V/60Hz with four sliding drawer racks and one shelf's worth (five cases) of 81-place Nalgene polycarbonate boxes (5026-0909) and one shelf's worth (five cases) of 1.8 mL sterile, antirotation, internally-threaded Nunc vials (377267)	\$14,883
TSX40086DPBRTSP	TSX400 19.4 cu. ft. freezer, 208-230V/60Hz with four sliding drawer racks and one shelf's worth (five cases) of 81-place Nalgene polycarbonate boxes (5026-0909) and one shelf's worth (five cases) of 1.8 mL sterile, antirotation, internally-threaded Nunc vials (377267)	\$14,883
TSX60086APBRTSP	TSX600 28.8 cu. ft. freezer, 115V/60Hz with six sliding drawer racks and one shelf's worth (seven cases) of 81-place Nalgene polycarbonate boxes (5026-0909) and one shelf's worth (seven cases) of 1.8 mL sterile, antirotation, internally-threaded Nunc vials (377267)	\$16,561
TSX60086DPBRTSP	TSX600 28.8 cu. ft. freezer, 208-230V/60Hz with six sliding drawer racks and one shelf's worth (seven cases) of 81-place Nalgene polycarbonate boxes (5026-0909) and one shelf's worth (seven cases) of 1.8 mL sterile, antirotation, internally-threaded Nunc vials (377267)	\$16,561

\* Valid in the United States only for orders placed between August 1, 2017 and December 31, 2017 or until promotional supplies are depleted, whichever comes first and only in connection with products identified above. Pricing in U.S. dollars. All pricing information and values based on current manufacturer's suggested list price. "Savings" or "Discount" indicated herein represent the maximum difference between the standard manufacturer's suggested list price of the product and the manufacturer's suggested list price for the product under this promotion. Actual savings may vary, subject to dealer participation. Cannot be combined with other discounts or promotion. Offer void where prohibited, licensed or restricted by federal, state, provincial, or local laws or regulation or agency/institutional policy. Other restrictions may apply. Customer acknowledges that this offer may include a discount or other price reduction that must be properly and accurately accounted for and reported by customer in accordance with all federal and state laws, including without limitation the federal anti-kickback law (42 C.F.R. § 1320a-7b(b)(3)(A)) and regulations thereunder (42 C.F.R. § 1001.952(h)).

**TSX Ultra-Low Freezers are available in 115V which means:**

- ✓ Lower power
- ✓ Just 8.5 AMPS on a 15 breaker
- ✓ Can be plugged into any standard outlet



Find out more at [thermofisher.com/tsx](http://thermofisher.com/tsx)

**For Research Use Only. Not for use in diagnostic procedures.**

**ThermoFisher**  
SCIENTIFIC