


CATALOG NO.	NOMINAL CAPACITY (ML)	MATERIALS	
		CONE	CLOSURE
001000	1000	PC	PP

SIZE CODE.....	-0010	
SIZE (NOM VOL mL)...	1000	
NECK FINISH (mm)....	13	
THREAD (T.P.I.).....	12	
NOM. WEIGHT W/CLOSURE (gms).....	227	
	in.	mm
A DIA (TOP O.D.)....	4.16 ±.02	105.7 ±0.5
B DIA (TOP O.D.)....	3.96 ±.02	100.6 ±0.5
C DIA (CLOSURE O.D.)	0.70 ±.02	17.8 ±0.5
D (HT W/O CLOSURE)..	17.93 ±.10	455.4 ±2.6
H (HT W/ CLOSURE)..	18.01 ±.10	457.5 ±2.6

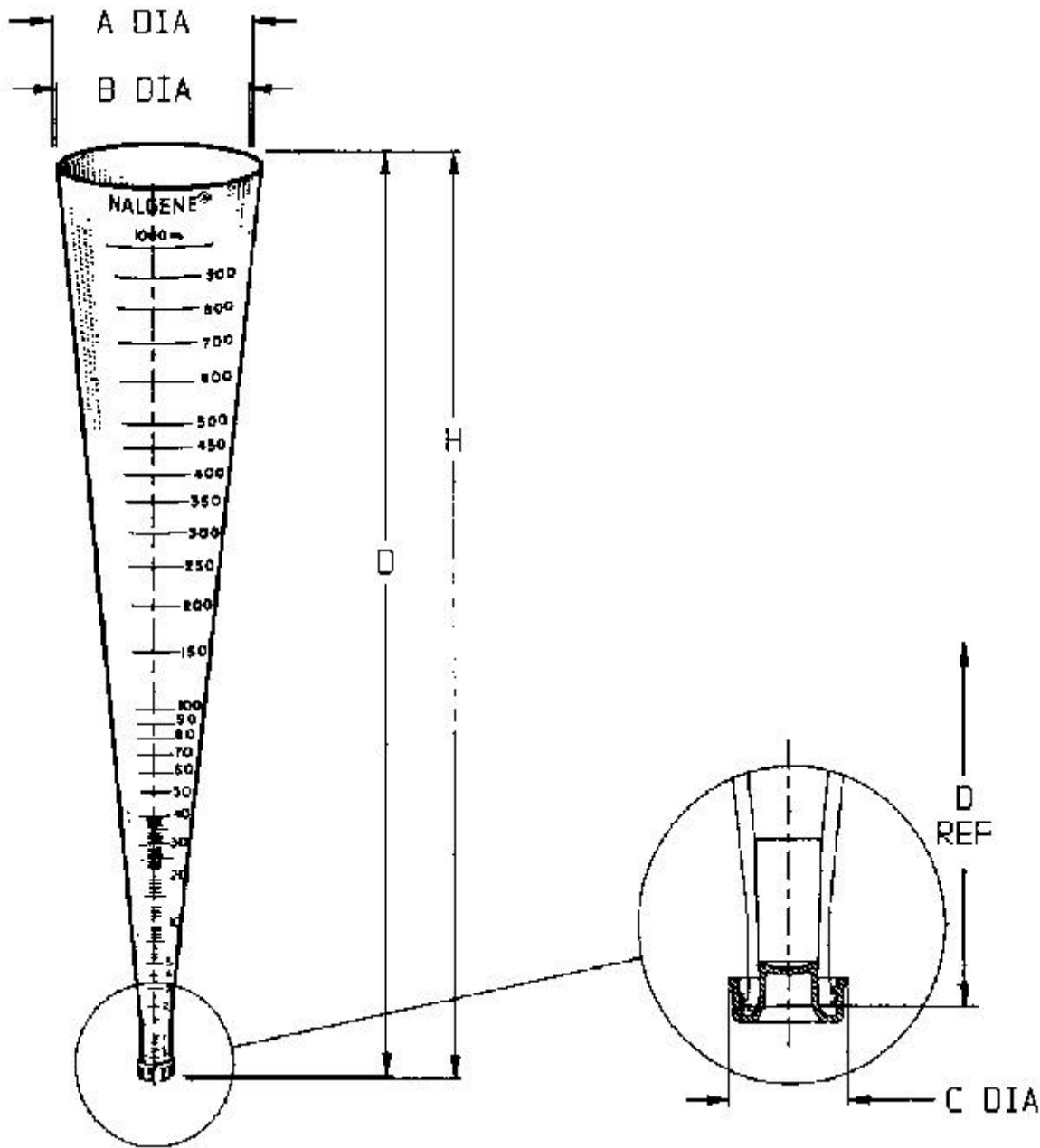

NOT TO SCALE

SPECS ON BACK

NOT TO SCALE

CONFIDENTIAL

THIS PRODUCT SPECIFICATION SHEET CONTAINS CONFIDENTIAL AND/OR PROPRIETARY INFORMATION AND IS TO BE USED ONLY FOR THE EXPRESSED PURPOSES AGREED UPON BY AN AUTHORIZED OFFICER OF THERMO FISHER SCIENTIFIC.

ThermoFisher
SCIENTIFIC

Thermo Fisher Scientific
75 Panorama Creek Drive
Rochester, NY 14625-2385, USA

MADE	MCC	APP'D	PVC	PSS 00-1000-0010	REV. —
CK'D	PVC		8/26/91		

DESCRIPTION:

IMHOFF SETTLING CONE

NOTES:

- ALL DIMENSIONS ARE NOMINAL AND IN INCHES AND MILLIMETERS UNLESS OTHERWISE NOTED.
- THIS IS NOT A PRODUCTION DRAWING, BUT IS FOR INFORMATIONAL PURPOSES ONLY, AND IS SUBJECT TO CHANGE WITHOUT NOTICE.