

CATALOG NO.	** NOMINAL CAPACITY, (mL)					MATERIAL
001203	400	600	1000	2000	4000	PMP


** FOR OTHER 5 SIZES (30, 50, 100, 150, 250mL), SEE PSS 00-1203-XXXX-1

SIZE CODE.....:	-0400		-0600		-1000	
NOM. CAP. (mL).....:	400		600		1000	
NOM. BRIM CAP (mL).:	600		870		1470	
NOM. WT. (gms).....:	53		73		110	
	INCH	MM	INCH	MM	INCH	MM
A (DIM. W/SPOUT)....:	4.23 ±0.04	107.4 ±1.0	4.73 ±0.04	120.1 ±1.0	5.59 ±0.05	142.0 ±1.3
B (O.D. AT LIP).....:	3.87 ±0.03	98.3 ±0.8	4.36 ±0.04	110.7 ±1.0	5.12 ±0.05	130.0 ±1.3
C (I.D. AT TOP).....:	3.50 ±0.03	88.9 ±0.8	3.99 ±0.04	101.3 ±1.0	4.77 ±0.04	121.2 ±1.0
D (I.D. AT BOTTOM).:	3.04 ±0.03	77.2 ±0.8	3.44 ±0.04	87.4 ±1.0	4.12 ±0.04	104.6 ±1.0
H (HEIGHT).....:	4.43 ±0.04	112.5 ±1.0	5.03 ±0.04	127.8 ±1.0	5.95 ±0.05	151.1 ±1.3
W.T. (NOM WALL THK):	0.07	1.8	0.08	2.0	0.08	2.0

SIZE CODE.....:	-2000		-4000	
NOM. CAP. (mL).....:	2000		4000	
NOM. BRIM CAP (mL).:	2880		5580	
NOM. WT. (gms).....:	185		280	
	INCH	MM	INCH	MM
A (DIM. W/SPOUT)....:	6.35 ±0.06	161.3 ±1.5	8.45 ±0.08	214.6 ±2.0
B (O.D. AT LIP).....:	6.12 ±0.06	155.4 ±1.5	7.63 ±0.07	193.8 ±1.8
C (I.D. AT TOP).....:	5.96 ±0.06	151.4 ±1.5	7.28 ±0.07	185.0 ±1.8
D (I.D. AT BOTTOM).:	5.05 ±0.06	128.3 ±1.5	6.18 ±0.06	157.0 ±1.5
H (HEIGHT).....:	7.54 ±0.07	191.5 ±1.8	9.8 ±0.1	249 ±3
W.T. (NOM WALL THK):	0.09	2.3	0.09	2.3

NOTES:

- ALL DIMENSIONS ARE NOMINAL AND IN INCHES AND MILLIMETERS UNLESS OTHERWISE NOTED.
- THIS IS NOT A PRODUCTION DRAWING, BUT IS FOR INFORMATIONAL PURPOSES ONLY, AND IS SUBJECT TO CHANGE WITHOUT NOTICE.

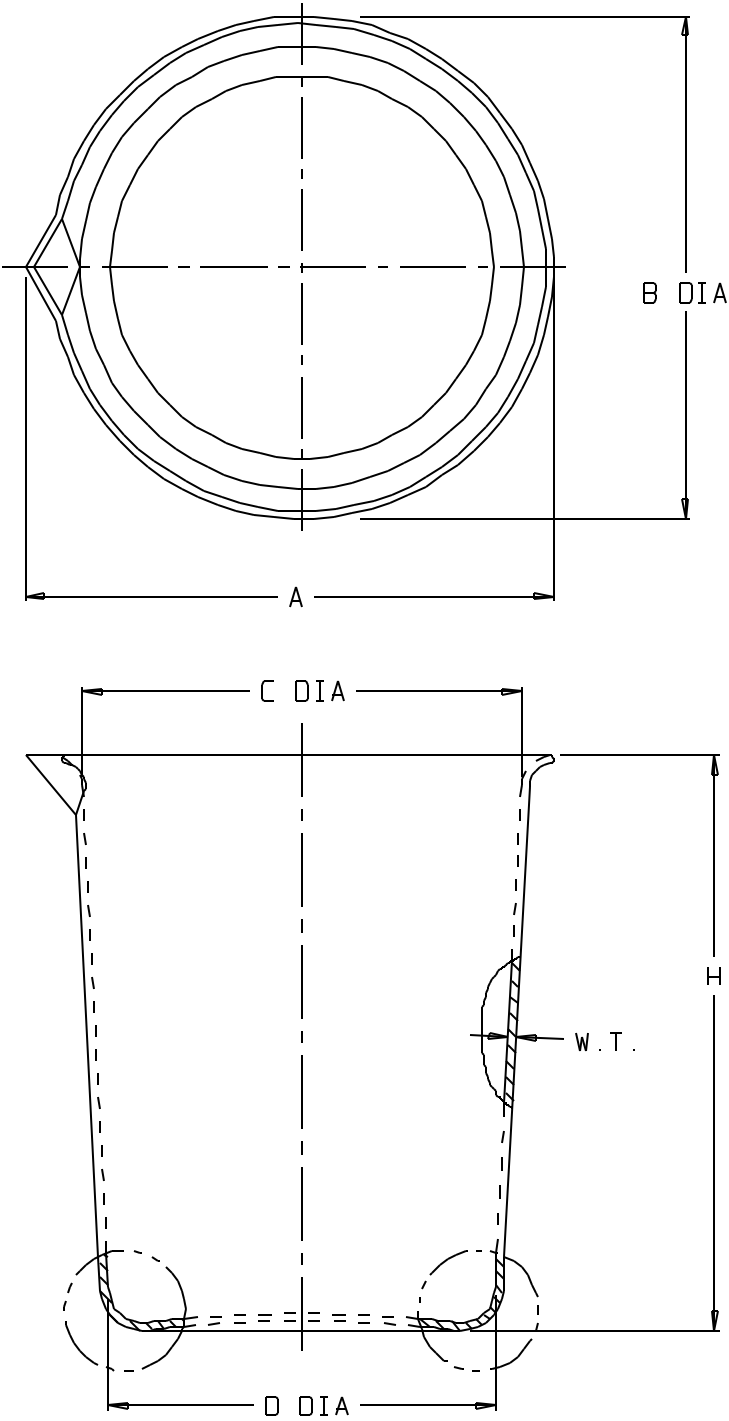

SPECS ON BACK

NOT TO SCALE

CONFIDENTIAL

THIS PRODUCT SPECIFICATION SHEET CONTAINS CONFIDENTIAL AND/OR PROPRIETARY INFORMATION AND IS TO BE USED ONLY FOR THE EXPRESSED PURPOSES AGREED UPON BY AN AUTHORIZED OFFICER OF THERMO FISHER SCIENTIFIC.

ThermoFisher
SCIENTIFIC

Thermo Fisher Scientific
75 Panorama Creek Drive
Rochester, NY 14625-2385, USA

MADE	JGJ	APP'D	PVC	PSS 00-1203-XXXX-2	REV 0595
CK'D	PVC		5/3/95		
DESCRIPTION:					
GRIFFIN LOW-FORM BEAKERS					