


CATALOG NUMBER	NOMINAL CAPACITY (mL)						MATERIALS		
							BOTTLE	CLOSURE	LINER (70mm ONLY)
004115	125	250	500	1000	2000	2800	PETG	HDPE (BLUE)	LDPE/FOAM

SIZE CODE.....:	-0125		-0250		-0500	
NOM. CAP.....:	125		250		500	
CLOSURE SIZE (mm).....:	38/430		38/430		45/430	
NOM. WEIGHT W/ CLOSURE (gms)....:	35		45		94	
	INCH	MM	INCH	MM	INCH	MM
A (NECK I.D.).....:	1.04	26.4	1.04	26.4	1.48	37.6
B (HT. W/ CLOSURE).....:	4.45	113.0	5.41	137.4	7.00	177.8
C (HT W/O CLOSURE)..:	4.30	109.2	5.27	133.9	6.83	173.5
D (DIA.).....:	2.61	66.3	3.25	82.6	4.00	101.6
W.T. (NOM. WALL THK.):	.03	0.7	.03	0.7	0.05	1.3

SIZE CODE.....:	-1000		-2000		-2800	
NOM. CAP.....:	1000		2000		2800	
CLOSURE SIZE (mm).....:	45/430		45/430		70	
NOM. WEIGHT W/ CLOSURE (gms).....:	130		180		275	
	INCH	MM	NOM	MM	NOM	MM
A (NECK I.D.).....:	1.40	35.6	1.40	35.6	2.49	63.2
B (HT. W/ CLOSURE).....:	8.70	221.0	10.75	273.1	9.42	239.3
C (HT W/O CLOSURE)..:	8.57	217.7	10.62	269.8	9.04	229.6
D (DIA.).....:	5.11	129.8	6.36	161.5	8.00	203.2
W.T. (NOM. WALL THK.):	.03	0.7	.03	0.7	.025	0.64

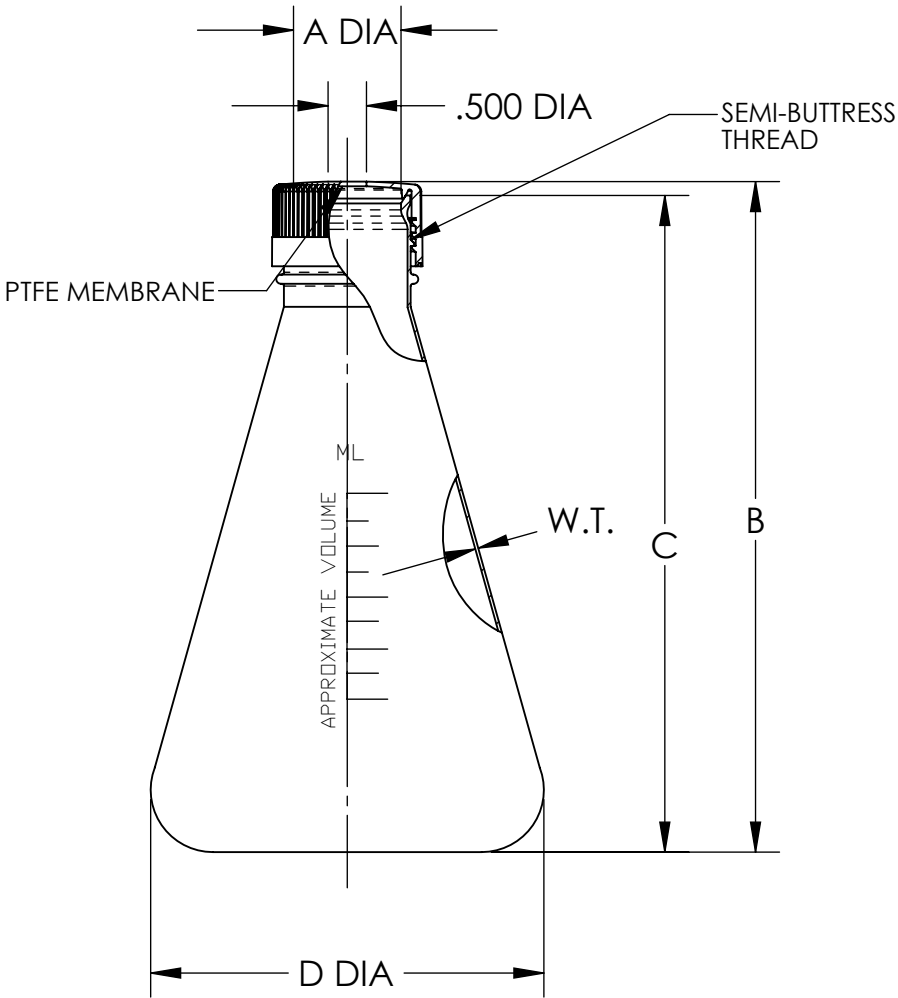

SPECS ON BACK

NOT TO SCALE

1. ALL DIMENSIONS ARE NOMINAL AND IN INCHES AND MILLIMETERS UNLESS OTHERWISE NOTED.
2. THIS IS NOT A PRODUCTION DRAWING, BUT IS FOR INFORMATIONAL PURPOSES ONLY, AND IS SUBJECT TO CHANGE WITHOUT NOTICE.

CONFIDENTIAL

THIS PRODUCT SPECIFICATION SHEET CONTAINS CONFIDENTIAL AND/OR PROPRIETARY INFORMATION AND IS TO BE USED ONLY FOR THE EXPRESSED PURPOSES AGREED UPON BY AN AUTHORIZED OFFICER OF THERMO FISHER SCIENTIFIC.

ThermoFisher
SCIENTIFIC

Thermo Fisher Scientific
75 Panorama Creek Drive
Rochester, NY 14625-2385, USA

MADE	TL	APP'D	GRP	PSS 00-4115-XXXX	REV. 0313
CK'D	CHL	3/5/13			

DESCRIPTION: STERILE DISPOSABLE FLASKS, VENTED