


CATALOG NUMBER.....:		177372	177380		
NO. OF WELLS.....:		1	2		
SUGGESTED WORKING VOL. (mL)....:		2.5 - 4.5	1.2 - 2.0		
CULTURE AREA WELL/cm.....:		9.4	4.2		
MATERIALS	COVER.....:	PS	PS		
	UPPER STRUCTURE....:	PS	PS		
	SLIDE.....:	GLASS	GLASS		
		INCH	MM	INCH	MM
A (SLIDE LENGTH).....:		2.98	75.7	2.98	75.7
B (SLIDE WIDTH).....:		1.02	25.9	1.02	25.9
C (SLIDE THICKNESS).....:		0.04	1.0	0.04	1.0
D (WELL LENGTH).....:		1.64	41.7	0.75	19.2
E (WELL WIDTH).....:		0.72	18.4	0.72	18.4
F (WELL INSIDE HEIGHT).....:		0.43	11.0	0.43	11.0
G (OVERALL HEIGHT).....:		0.51	13.0	0.51	13.0

CATALOG NUMBER.....:		177399	177402		
NO. OF WELLS.....:		4	8		
SUGGESTED WORKING VOL. (mL)...:		0.5 - 0.9	0.2 - 0.4		
CULTURE AREA WELL/cm.....:		1.8	0.8		
MATERIALS	COVER.....:	PS	PS		
	UPPER STRUCTURE:	PS	PS		
	SLIDE.....:	GLASS	GLASS		
		INCH	MM	INCH	MM
A (SLIDE LENGTH).....:		2.98	75.7	2.98	75.7
B (SLIDE WIDTH).....:		1.02	25.9	1.02	25.9
C (SLIDE THICKNESS).....:		0.04	1.0	0.04	1.0
D (WELL LENGTH).....:		0.27	7.0	0.28	7.1
E (WELL WIDTH).....:		0.72	18.3	0.28	7.1
F (WELL INSIDE HEIGHT).....:		0.43	11.0	0.43	11.0
G (OVERALL HEIGHT).....:		0.51	13.0	0.51	13.0

- NOTES:
- ALL DIMENSIONS ARE NOMINAL AND IN INCHES AND MILLIMETERS UNLESS OTHERWISE NOTED.
 - THIS IS NOT A PRODUCTION DRAWING, BUT IS FOR INFORMATIONAL PURPOSES ONLY, AND IS SUBJECT TO CHANGE WITHOUT NOTICE.

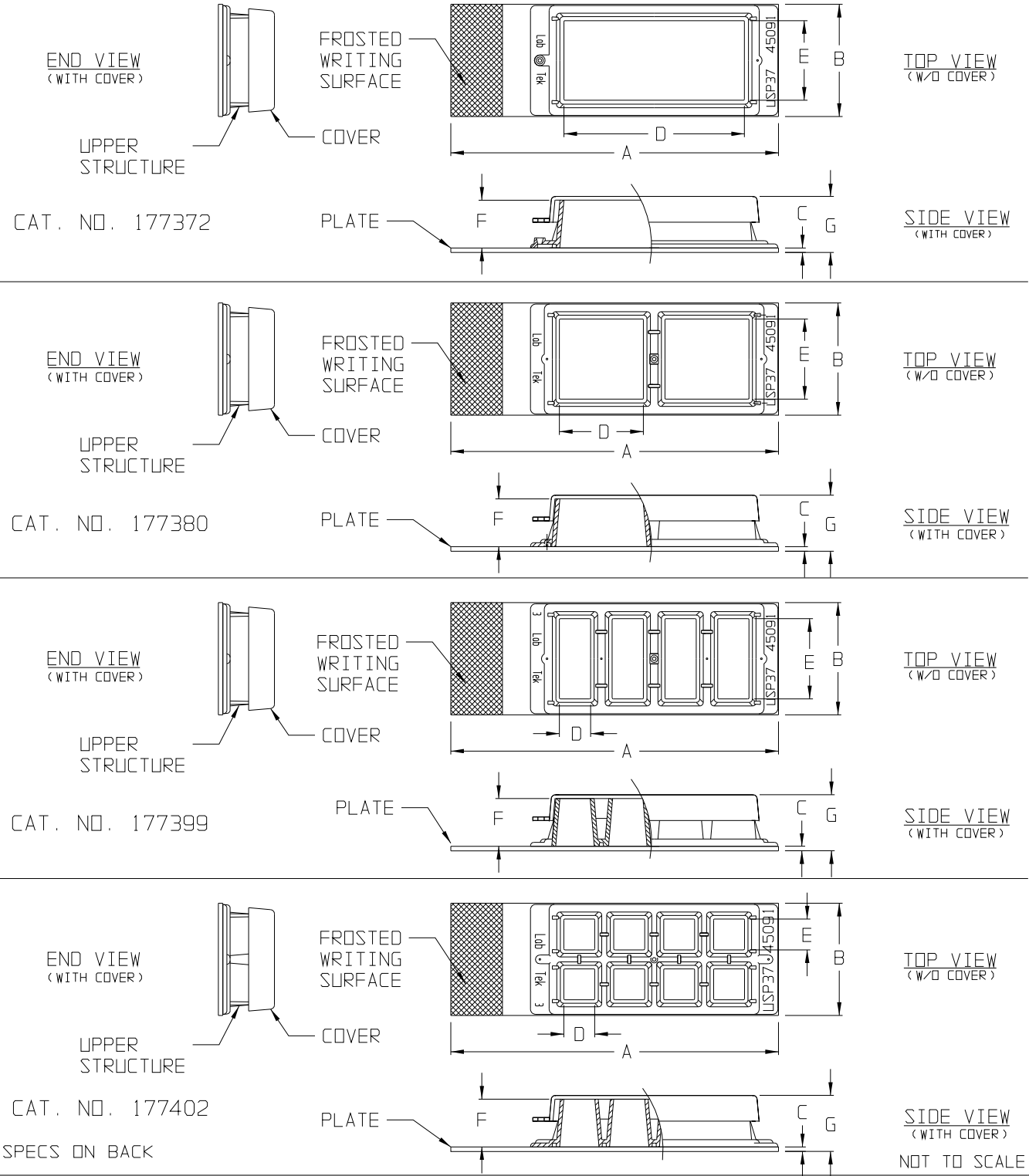

CONFIDENTIAL

THIS PRODUCT SPECIFICATION SHEET CONTAINS CONFIDENTIAL AND/OR PROPRIETARY INFORMATION AND IS TO BE USED ONLY FOR THE EXPRESSED PURPOSES AGREED UPON BY AN AUTHORIZED OFFICER OF THERMO FISHER SCIENTIFIC.

ThermoFisher
SCIENTIFIC

Thermo Fisher Scientific
75 Panorama Creek Drive
Rochester, NY 14625-2385, USA

MADE	PMP	APP'D	PWC	PSS 177XXX-1	REV. 0516
CK'D	JC		5/3/16		
DESCRIPTION:					
LAB-TEK® CHAMBER SLIDE™ SYSTEM					