


CATALOG NO. .... :		3120-42	
SIZE NOM VOL. (mL) .... :		1000	
NOMINAL BRIM CAP. (mL) ... :		1,240	
MATERIALS	BOTTLE .... :	PC	
	CLOSURE .... :	WHITE PP	
	CLOSURE LINER. :.	SILICONE RUBBER	
NECK FINISH .... :		48mm DOUBLE START THR'D	
THREAD (T.P.I.) .... :		3	
NOM. WEIGHT W/ CLOSURE (gms) .... :		150	
		INCH	CM (REF)
A (NECK I.D.) .... :		1.46±.03	3.7±.08
B (HT. W/O CLOSURE) .... :		7.76±.15	19.7±.38
C (HT. W/ CLOSURE) .... :		7.90±.2	20.1±.51
D (SQUARE) .... :		3.86±.15	9.8±.38
W.T. (NOM. WALL THK) .... :		.04	0.1

NOTES:

1. ALL DIMENSIONS ARE NOMINAL AND IN INCHES AND MILLIMETERS UNLESS OTHERWISE NOTED.
2. THIS IS NOT A PRODUCTION DRAWING, BUT IS FOR INFORMATIONAL PURPOSES ONLY, AND IS SUBJECT TO CHANGE WITHOUT NOTICE.

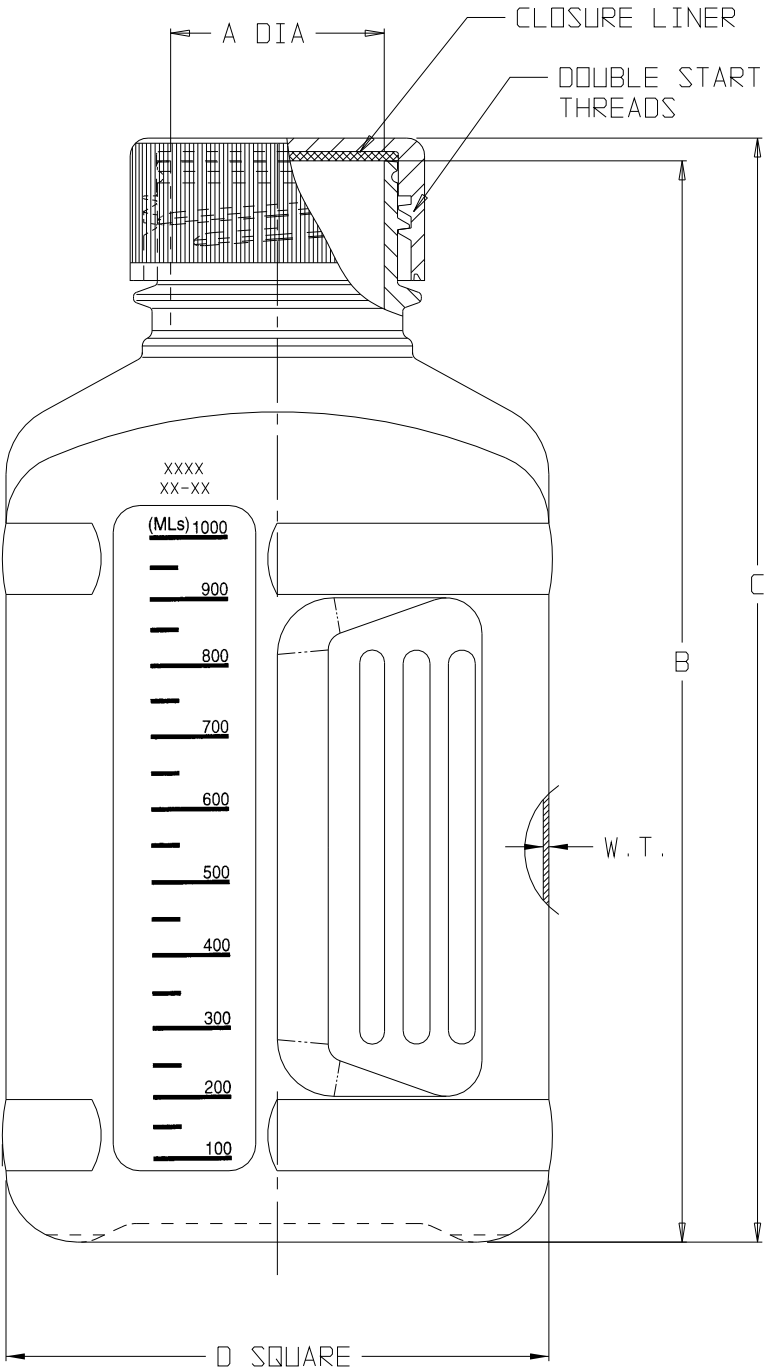

SPECS ON BACK

NOT TO SCALE

CONFIDENTIAL

THIS PRODUCT SPECIFICATION SHEET CONTAINS CONFIDENTIAL AND/OR PROPRIETARY INFORMATION AND IS TO BE USED ONLY FOR THE EXPRESSED PURPOSES AGREED UPON BY AN AUTHORIZED OFFICER OF THERMO FISHER SCIENTIFIC.

ThermoFisher  
SCIENTIFIC

Thermo Fisher Scientific  
75 Panorama Creek Drive  
Rochester, NY 14625-2385, USA

MADE	PMP	APP'D	PSS 3120-42	REV.
CK'D	JC	PWC 12/16		1216
DESCRIPTION:				
BIOTAINER BOTTLE, PC, 1L				