


CATALOG NO.....:	3500-20	
SIZE (NOM VOL mL)...:	20	
MATERIALS	BOTTLE....:	LIGHT BLUE TINT - PC
	CLOSURE...:	WHITE PP
	LINER.....:	WHITE SILICONE
NECK FINISH (mm)...:	20-415	
THREAD (T.P.I.)....:	8	
NOM. WEIGHT W/ CLOSURE (gms)...:	13	
	INCH	MM
A (CROWN O.D.)....:	0.69 ±.01	17.5 ±.3
B (NECK I.D.)....:	0.45 ±.01	11.4 ±.3
C (HT. W/O CLOSURE):	2.46 ±.02	62.5 ±.5
D (DIA).....:	1.17 ±.01	29.7 ±.3
E (HT. W/ CLOSURE)..:	2.57 ±.02	65.3 ±.5
W.T.(NOM WALL THK)..:	0.05	1.3

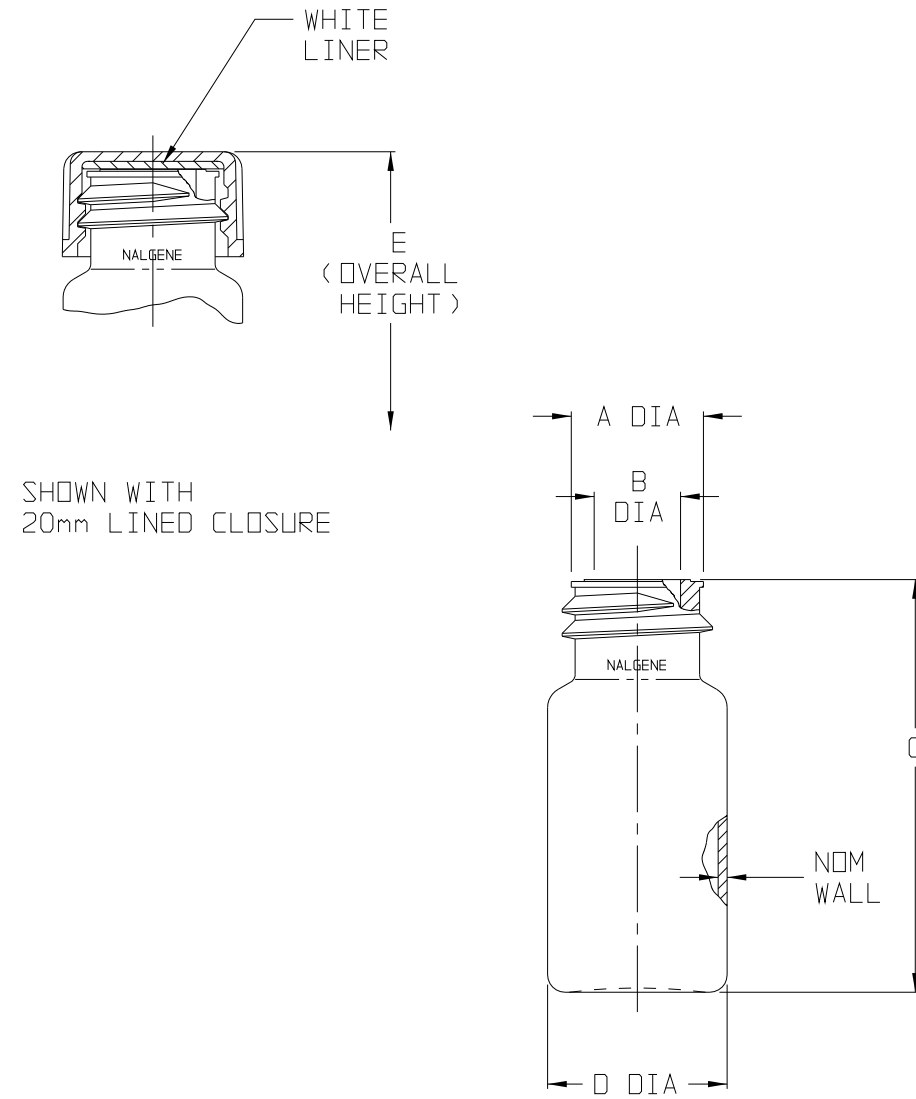

SPECS ON BACK

NOT TO SCALE

NOTES:

1. ALL DIMENSIONS ARE NOMINAL AND IN INCHES AND MILLIMETERS UNLESS OTHERWISE NOTED.
2. THIS IS NOT A PRODUCTION DRAWING, BUT IS FOR INFORMATIONAL PURPOSES ONLY, AND IS SUBJECT TO CHANGE WITHOUT NOTICE.

CONFIDENTIAL

THIS PRODUCT SPECIFICATION SHEET CONTAINS CONFIDENTIAL AND/OR PROPRIETARY INFORMATION AND IS TO BE USED ONLY FOR THE EXPRESSED PURPOSES AGREED UPON BY AN AUTHORIZED OFFICER OF THERMO FISHER SCIENTIFIC.

ThermoFisher
SCIENTIFIC

Thermo Fisher Scientific
75 Panorama Creek Drive
Rochester, NY 14625-2385, USA

MADE	PB	APP'D	GRP	PSS 00-3500-20	REV. 0212
CK'D	KOW		2/8/12		
DESCRIPTION: 20mL VALIDATION VIAL					