


CATALOG NO.....:	2670-0075		2670-0150		2670-0300	
SIZE (in/mm).....:	.75 MINI/19		1.5 TRI/38		3 TRI/76	
MATERIAL.....:	PVDF					
NOM. WEIGHT (gms)...	26		120		280	
	INCH	MM	INCH	MM	INCH	MM
A (DIA).....:	0.98	24.9	2.00	50.8	3.55	90.2
B (WIDTH).....:	1.50	38.1	2.80	71.1	4.50	114.3
C (HEIGHT).....:	0.82	20.8	1.30	33.0	1.60	40.6
D (RING THICKNESS):	0.39	9.9	0.39	9.9	0.39	9.9

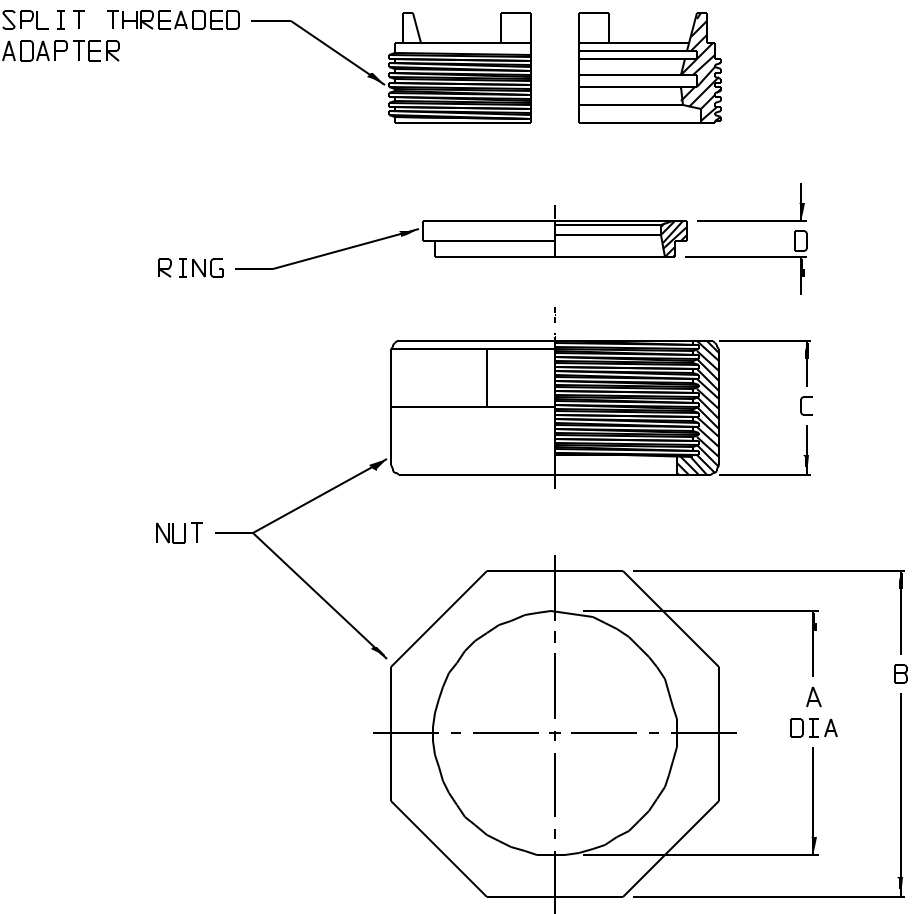

SPECS ON BACK

NOT TO SCALE

- NOTES:
- 1. ALL DIMENSIONS ARE NOMINAL AND IN INCHES AND MILLIMETERS UNLESS OTHERWISE NOTED.
 - 2. THIS IS NOT A PRODUCTION DRAWING, BUT IS FOR INFORMATIONAL PURPOSES ONLY, AND IS SUBJECT TO CHANGE WITHOUT NOTICE.

CONFIDENTIAL

THIS PRODUCT SPECIFICATION SHEET CONTAINS CONFIDENTIAL AND/OR PROPRIETARY INFORMATION AND IS TO BE USED ONLY FOR THE EXPRESSED PURPOSES AGREED UPON BY AN AUTHORIZED OFFICER OF THERMO FISHER SCIENTIFIC.

ThermoFisher
SCIENTIFIC

Thermo Fisher Scientific
75 Panorama Creek Drive
Rochester, NY 14625-2385, USA

MADE	PB/MC	APP'D	PVC	PSS 00-2670-0XXX	REV. 0502
CHK'D	PVC		5/16/02		
DESCRIPTION: TRUE UNION CLAMPS					