


CATALOG NO.....:	3120
BOTTLE MAT'L.....:	PP
CLOSURE MAT'L.....:	PP
SIZE CODE.....:	-1010
SIZE (NOM VOL mL)....:	1000
NOM. BRIM CAP. (mL)..:	1020
NECK FINISH (mm).....:	63-415
THREAD (T.P.I.).....:	6
NOM.WEIGHT W/CLOSURE (gms).....:	85
A (NECK I.D.).....:	2.07 ±.03
B (HT. W/CLOSURE)....:	6.60 ±.05
C (HT W/O CLOSURE)...:	6.40 ±.05
D (DIA).....:	3.82 ±.04
W.T. (NOM. WALL THK):	0.060

NOTES:

1. ALL DIMENSIONS ARE NOMINAL AND IN INCHES AND MILLIMETERS UNLESS OTHERWISE NOTED.
2. THIS IS NOT A PRODUCTION DRAWING, BUT IS FOR INFORMATIONAL PURPOSES ONLY, AND IS SUBJECT TO CHANGE WITHOUT NOTICE.

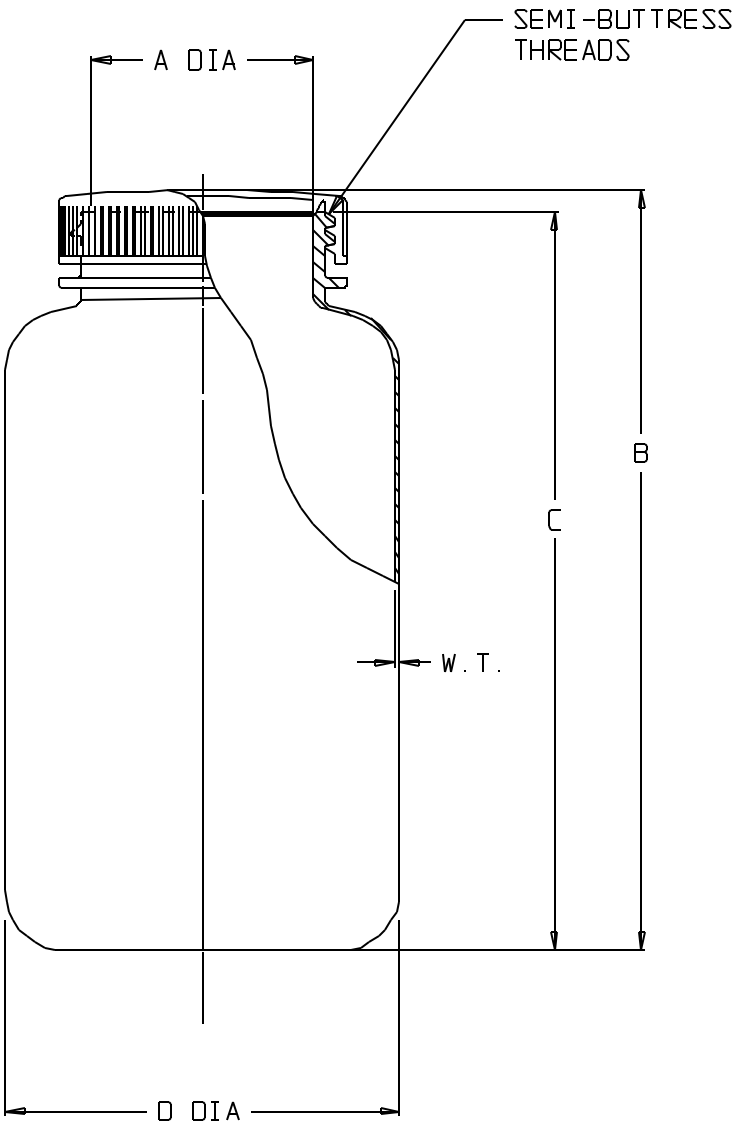

SPECS ON BACK

NOT TO SCALE

CONFIDENTIAL

THIS PRODUCT SPECIFICATION SHEET CONTAINS CONFIDENTIAL AND/OR PROPRIETARY INFORMATION AND IS TO BE USED ONLY FOR THE EXPRESSED PURPOSES AGREED UPON BY AN AUTHORIZED OFFICER OF THERMO FISHER SCIENTIFIC.

ThermoFisher
SCIENTIFIC

Thermo Fisher Scientific
75 Panorama Creek Drive
Rochester, NY 14625-2385, USA

MADE	TL	APP'D	PSS 00-3120-1010-S	REV. 0909
CK'D	PB	GRP 9/30/09		
DESCRIPTION: WIDE MOUTH, ROUND CENTRIFUGE BOTTLES				