


CATALOG NO.	NOMINAL CAPACITY, (mL)			MATERIALS	
				BOTTLE	CLOSURE
3122	250	500	1000	PC	PP

SIZE CODE.....:	-0250		-0500	
NOM. CAP. (mL).....:	250		500	
CLOSURE SIZE (mm)....:	38		48	
	INCH	MM	INCH	MM
A (NECK I.D.).....:	1.14	29.0	1.41	35.8
B (HT. W/CLOSURE)....:	4.93 ± 0.04	125.2 ± 1.0	6.65 ± 0.05	168.9 ± 1.3
C (DIA).....:	2.432 ^{+0.000} _{-.020}	61.77 ^{+0.00} _{-.51}	2.737 ^{+0.000} _{-.030}	69.52 ^{+0.00} _{-.76}

SIZE CODE.....:	-1000		-1010	
NOM. CAP. (mL).....:	1000		1000	
CLOSURE SIZE (mm)....:	63		63	
	INCH	MM	INCH	MM
A (NECK I.D.).....:	2.07	52.6	2.07	52.6
B (HT. W/CLOSURE)....:	6.97 ± 0.06	177.0 ± 1.5	6.88 ± 0.06	169.7 ± 1.5
C (DIA).....:	3.865 ^{+0.000} _{-.065}	98.17 ^{+0.00} _{-1.65}	3.865 ^{+0.000} _{-.065}	98.17 ^{+0.00} _{-1.65}

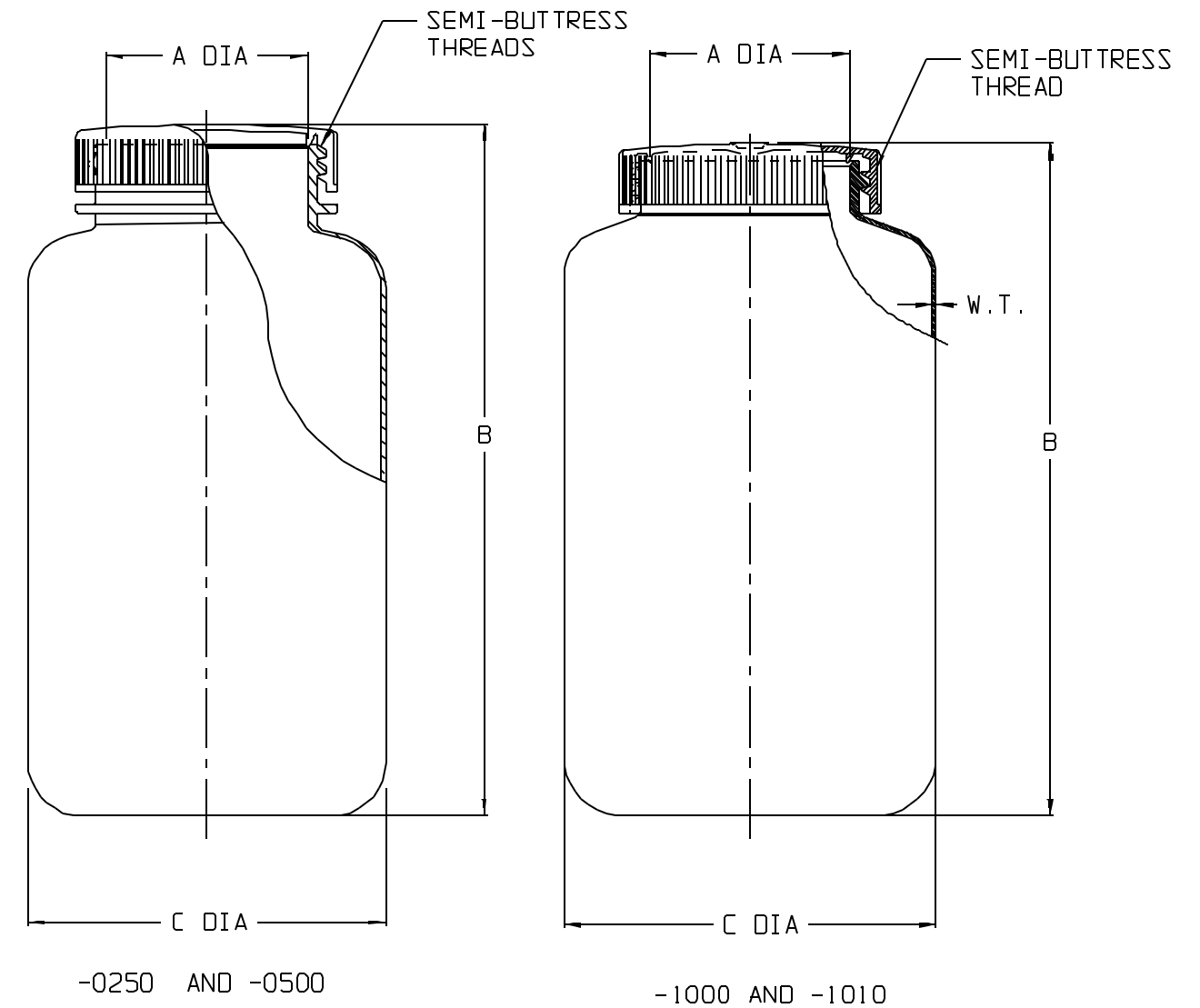

SPECS ON BACK

NOT TO SCALE

NOTES:

1. ALL DIMENSIONS ARE NOMINAL AND IN INCHES AND MILLIMETERS UNLESS OTHERWISE NOTED.
2. THIS IS NOT A PRODUCTION DRAWING, BUT IS FOR INFORMATIONAL PURPOSES ONLY, AND IS SUBJECT TO CHANGE WITHOUT NOTICE.

CONFIDENTIAL

THIS PRODUCT SPECIFICATION SHEET CONTAINS CONFIDENTIAL AND/OR PROPRIETARY INFORMATION AND IS TO BE USED ONLY FOR THE EXPRESSED PURPOSES AGREED UPON BY AN AUTHORIZED OFFICER OF THERMO FISHER SCIENTIFIC.

ThermoFisher
SCIENTIFIC

Thermo Fisher Scientific
75 Panorama Creek Drive
Rochester, NY 14625-2385, USA

MADE	TL	APP'D	GRP	PSS 00-3122-XXXX-1	REV.
CK'D	PB		9/30/09		0909

DESCRIPTION:

CENTRIFUGE BOTTLES