


CATALOG NO.....		6421-0010	
MATERIAL	BODY.....	PP	
	O-RINGS...	TEFLON TFE	
NOM. WT. (gm).....		68	
	INCH	MM	
A (LENGTH).....	3.39	86.1	
B (HANDLE DIA).....	2.25	57.2	
C	1.16	29.5	
D (SPIGOT DIA).....	0.68	17.3	
E (OVERALL HEIGHT)...	2.78	70.6	
F (BODY DIA).....	1.4	36	
G (SPIGOT LENGTH)...	0.95	24.1	
H DIM.....	1.6	41	

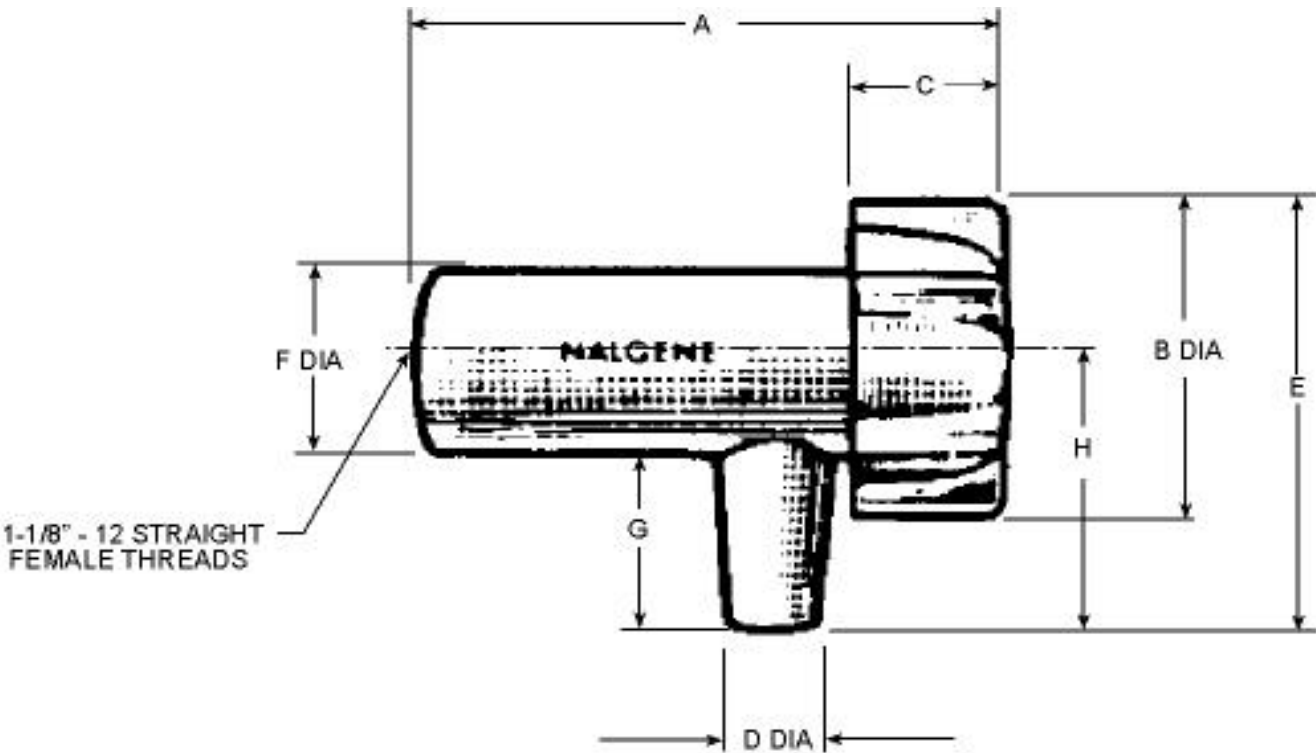

SPECS ON BACK

NOT TO SCALE

- NOTES:
1. ALL DIMENSIONS ARE NOMINAL AND IN INCHES AND MILLIMETERS UNLESS OTHERWISE NOTED.
 2. THIS IS NOT A PRODUCTION DRAWING, BUT IS FOR INFORMATIONAL PURPOSES ONLY, AND IS SUBJECT TO CHANGE WITHOUT NOTICE.

CONFIDENTIAL

THIS PRODUCT SPECIFICATION SHEET CONTAINS CONFIDENTIAL AND/OR PROPRIETARY INFORMATION AND IS TO BE USED ONLY FOR THE EXPRESSED PURPOSES AGREED UPON BY AN AUTHORIZED OFFICER OF THERMO FISHER SCIENTIFIC.

ThermoFisher SCIENTIFIC		Thermo Fisher Scientific 75 Panorama Creek Drive Rochester, NY 14625-2385, USA		
MADE	MC	APP'D	PVC	REV.
CK'D	PVC	9/14/01	PSS 00-6421-0010	0901
DESCRIPTION:				
NEEDLE-TYPE TANK SPIGOT				