

CATALOG NO.	NOMINAL CAPACITY (LITERS)				MATERIAL
	2	2.8	3.1	5	
006902					PP


SIZE CODE	-1000		-2000	
	NOM. WEIGHT (gms)		225	
	INCH	MM	INCH	MM
A (HEIGHT)	2.6	66	4.1	104
B (TOP OUTSIDE LENGTH)	10.4	264	10.3	262
C (TOP OUTSIDE WIDTH)	6.3	161	6.3	161
D (TOP INSIDE LENGTH)	9.3	236	9.3	236
E (TOP INSIDE WIDTH)	5.3	135	5.3	135
F (BOTTOM INSIDE LENGTH)	8.0	203	8.3	211
G (BOTTOM INSIDE WIDTH)	4.0	102	4.3	109

SIZE CODE	-3000		-5000	
	NOM. WEIGHT (gms)		425	
	INCH	MM	INCH	MM
A (HEIGHT)	2.6	66	4.2	107
B (TOP OUTSIDE LENGTH)	10.4	264	10.4	264
C (TOP OUTSIDE WIDTH)	12.8	325	12.7	323
D (TOP INSIDE LENGTH)	11.8	300	11.7	297
E (TOP INSIDE WIDTH)	9.4	239	9.3	236
F (BOTTOM INSIDE LENGTH)	10.4	264	10.5	267
G (BOTTOM INSIDE WIDTH)	8.1	206	8.2	208

-CONFIDENTIAL-  
DO NOT DUPLICATE

NOTES:

1. ALL DIMENSIONS ARE NOMINAL AND IN INCHES AND MILLIMETERS UNLESS OTHERWISE NOTED.
2. THIS IS NOT A PRODUCTION DRAWING, BUT IS FOR INFORMATIONAL PURPOSES ONLY, AND IS SUBJECT TO CHANGE WITHOUT NOTICE.

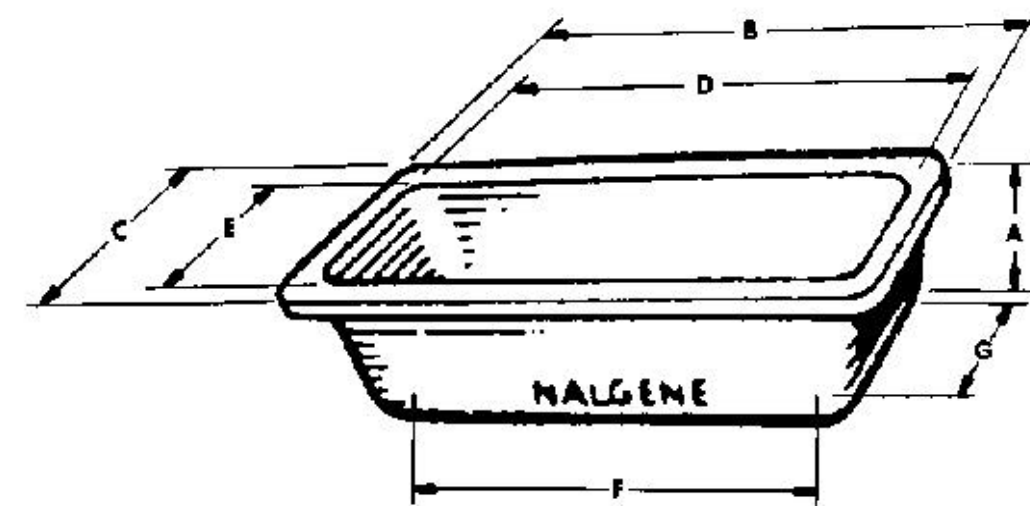

SPECS ON BACK

NOT TO SCALE

CONFIDENTIAL

THIS PRODUCT SPECIFICATION SHEET CONTAINS CONFIDENTIAL AND/OR PROPRIETARY INFORMATION AND IS TO BE USED ONLY FOR THE EXPRESSED PURPOSES AGREED UPON BY AN AUTHORIZED OFFICER OF THERMO FISHER SCIENTIFIC.

**ThermoFisher**  
SCIENTIFIC

Thermo Fisher Scientific  
75 Panorama Creek Drive  
Rochester, NY 14625-2385, USA

MADE	MCC	APP'D	PVC	PSS 00-6902-XXXX	REV.	0296
CK'D	PVC		2/27/06			

DESCRIPTION:

AUTOCLAVABLE PANS