



Thermo Scientific Nalgene Versi-Dry Surface Protectors

protect laboratory surfaces


from damage and contamination

Nalgene® Versi-Dry® Surface Protectors can help make your lab a safer place by quickly absorbing spills and cushioning breakable labware. Use Versi-Dry as a bench protector, shelf liner, cabinet liner or for wiping up isolated spills. The skid-resistant polyethylene backing protects your bench-top and other lab surfaces from damage and contamination caused by liquid drips and spills. The cloth-like top layer is long-lasting and will not fall apart, even when wet.

Thermo
SCIENTIFIC

Thermo Scientific Nalgene Versi-Dry Surface Protectors

- Thousands of Thirsty-Cells® quilted into the surface quickly absorb spills. Available in white regular absorbency (750ml/sq²) or blue super absorbency (1,050 ml/sq²)
- Cushioned surface minimizes breakage of fragile glassware when dropped or tipped over
- Low-pile sheets lie flat and are skid-resistant helping to stabilize labware and prevent tipping
- Remains flat and won't curl up or warp with repeated wetting and drying
- Polyethylene backing prevents chemicals from breaking through to protected surfaces beneath

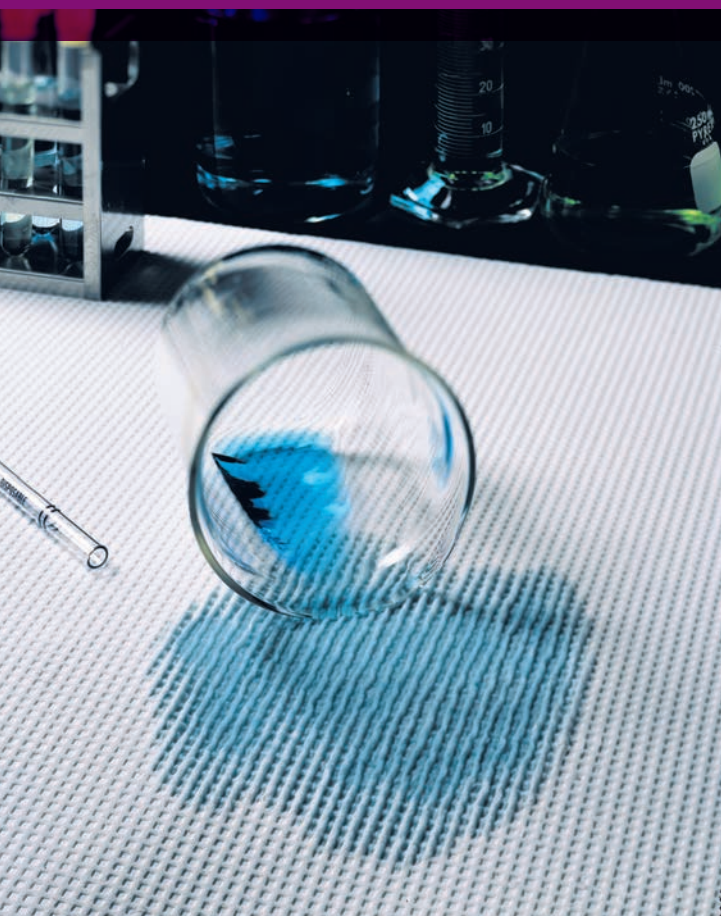

Get a free sample of Nalgene Super Versi-Dry.
Go to www.thermoscientific.com/breaktheglass
for details.

Versi-Dry resists the following chemical spills:

Acetone	Methyl Iso Butyl Ketone (MIB)
Ammonium Hydroxide, 30%*	Mineral Spirits
Chlorine Bleach	Nitric Acid, 10%*
Chlorobenzene	Phosphoric Acid, 10%*
Chloroform	Potassium Hydroxide, 30%*
Ethanolamine	Sulfuric Acid, 10%
Hydrochloric Acid, 10%*	Sodium Hydroxide, 10N*
Hydrofluoric Acid, 10%*	Toluene
Methylene Chloride	Xylene
Methyl Ethyl Ketone (MEK)	

*Highest concentration tested

Nalgene Regular Versi-Dry Surface Protectors-absorbs 750ml/sq²

Cat. No.	L x W	No. per case
Mat		
62080-00	46 x 51 cm (18 x 20 in)	350
Dispenser Rolls		
62050-00	51 cm x 91 m (20 in x 300 ft)	1
62070-00	51 cm x 30 m (20 in x 100 ft)	4
Rolls		
62060-00	51 cm x 91 m (20 in x 300 ft)	2
62065-00	51 cm x 46 m (20 in x 150 ft)	2

Nalgene Super Versi-Dry Surface Protectors – absorbs 1,050ml/sq²

Cat. No.	Description	L x W	No. Per Case
Mats			
74018-00		46 x 51 cm (18 x 20 in)	350
74040-00		46 x 102 cm (18 x 40 in)	175
74043-00	Table Mat	51 x 110 cm (20 x 43 in)	150
74200-00	Floor Mat	102 x 508 cm (40 x 200 in)	1
74218-00	Fume Hood Mat	46 x 51 cm (18 x 20 in)	100
74240-00	Floor Mat	46 x 102 cm (18 x 40 in)	50
Rolls			
74000-00		51 cm x 76 m (20 in x 250 ft)	1
74050-00		30 x 51 cm (20 in x 100 ft)	4

© 2012 Thermo Fisher Scientific Inc. All rights reserved. All trademarks are the property of ThermoFisher Scientific Inc. and its subsidiaries.

www.thermoscientific.com/versidry

ANZ: Australia: 1300 735 292, New Zealand: 0800 933 966; **Asia:** China Toll-free: 800-810-5118 or 400-650-5118; India: +91 22 6716 2200, India Toll-free: 1 800 22 8374; Japan: +81-3-5826-1616; Other Asian countries: 65 68729717
Europe: Austria: +43 1 801 40 0; Belgium: +32 2 482 30 30; Denmark: +45 4631 2000; France: +33 2 2803 2180; Germany: +49 6184 90 6940, Germany Toll-free: 08001-536 376; Italy: +39 02 95059 552 or 434-254-375; Netherlands: +31 76 571 4440; Nordic/Baltic countries: +358 9 329 10200; Russia/CIS: +7 (812) 703 42 15; Spain/Portugal: +34 93 223 09 18; Switzerland: +41 44 454 12 12; UK/Ireland: +44 870 609 9203
North America: USA/Canada +1 585 586 8800; USA Toll-free: 800 625 4327
South America: USA sales support: +1 585 899 7198 **Countries not listed:** +49 6184 90 6940 or +33 2 2803 2000

Thermo
SCIENTIFIC

Part of Thermo Fisher Scientific