


| CATALOG NUMBER | NOMINAL CAPACITY (mL) | MATERIALS | | | |
|----------------|-----------------------|-----------|----------|-----------------|----------|
| | | BOTTLE | CLOSURE | PLUG | O-RING |
| 3141 | 1000 | PPCO | PPE+HIPS | PP-GLASS FILLED | SILICONE |

| | | |
|--------------------------|----------------|------------|
| SIZE CODE.....: | 1002/1006/1024 | |
| NOM. CAP.....: | 1000 | |
| CLOSURE SIZE (mm).....: | 84.5 | |
| | INCH | MM |
| A (NECK I.D.).....: | 2.82 ±.02 | 71.6 ±0.5 |
| B (HT. W/ CLOSURE).....: | 7.71 ±.06 | 195.8 ±1.5 |
| C (DIA.).....: | 3.82 ±.05 | 97.0 ±1.3 |
| MIN WALL THICKNESS...: | .08 | 2.0 |

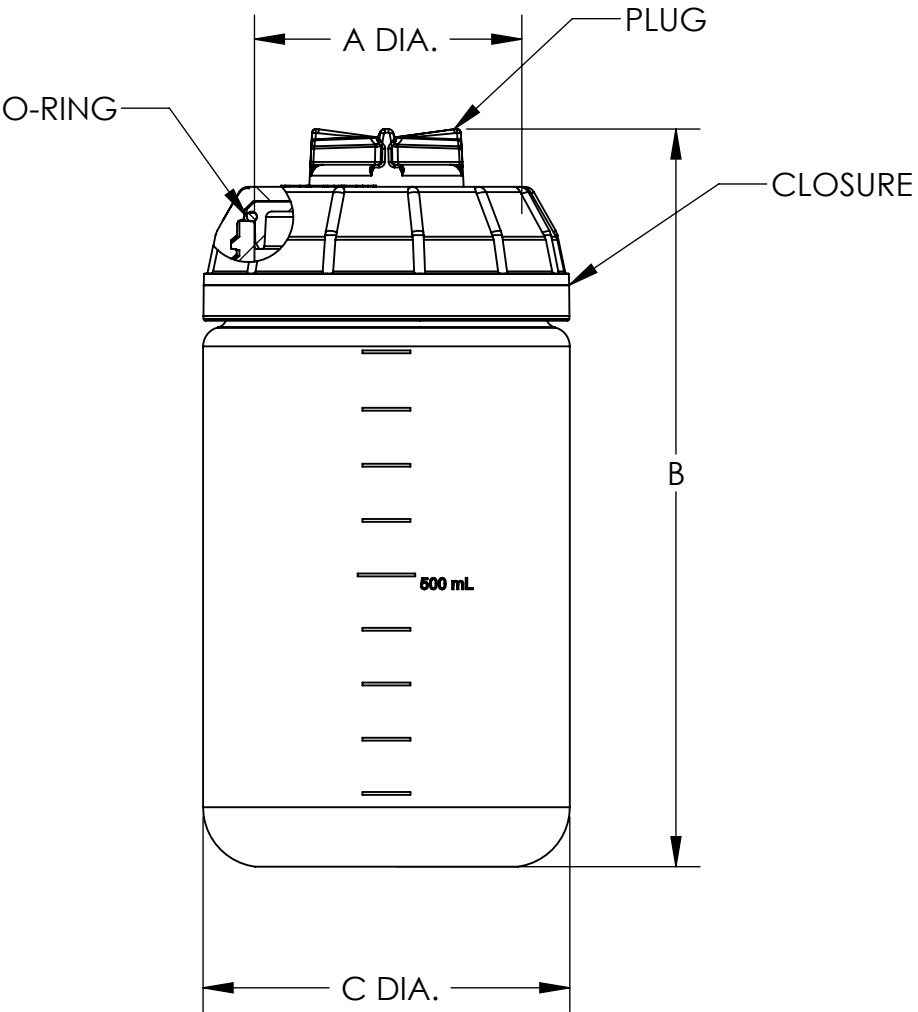

SPECS ON BACK

NOT TO SCALE

1. ALL DIMENSIONS ARE NOMINAL AND IN INCHES AND MILLIMETERS UNLESS OTHERWISE NOTED.
2. THIS IS NOT A PRODUCTION DRAWING, BUT IS FOR INFORMATIONAL PURPOSES ONLY, AND IS SUBJECT TO CHANGE WITHOUT NOTICE.

CONFIDENTIAL

THIS PRODUCT SPECIFICATION SHEET CONTAINS CONFIDENTIAL AND/OR PROPRIETARY INFORMATION AND IS TO BE USED ONLY FOR THE EXPRESSED PURPOSES AGREED UPON BY AN AUTHORIZED OFFICER OF THERMO FISHER SCIENTIFIC.

ThermoFisher
S C I E N T I F I C

Thermo Fisher Scientific
75 Panorama Creek Drive
Rochester, NY 14625-2385, USA

| | | | | | |
|------|-----|---------|-----|-----------------|--------------|
| MADE | PB | APP'D | GRP | PSS 003141-10XX | REV. 0807 |
| CK'D | KOW | 8/24/07 | | | |

DESCRIPTION: 1L HIGH SPEED CENTRIFUGE BOTTLE